


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed r/min		* SKF Explorer bearir
mm			kN		r/min		-
26,988	50,292	14,224	26	30	10000	15000	L 44649/610/Q

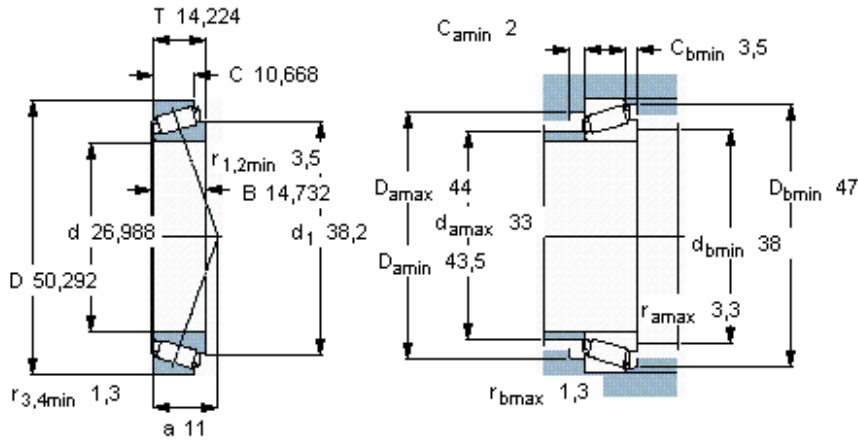

Calculation factors

e 0,37
 Y 1,6
 Y₀ 0,9