


Datasheet

Midget Groove LED Indicator Lamp

RS Stock number 204-136

Dimensions (mm):

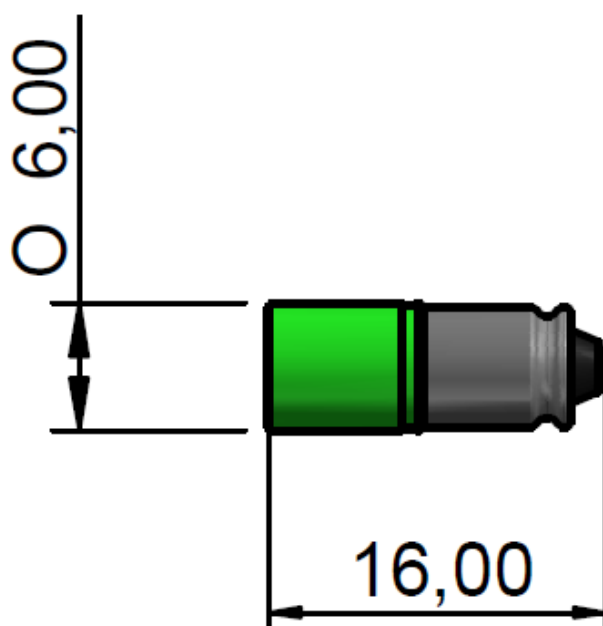

Specifications:

LED/Multiled	LED
Mounting Size	TI ¾
Mounting Finish	-
Protection	-
Mount Holder	Midget Groove
Chip Qty	1
Indicator Colour	Green
Optimum Voltage (V)	12V ac/dc
Rectifier	Half Wave

AC Current	7mA
DC Current	15mA
Voltage Tolerance	10%
Optimum Temperature	-30°C ... +60°C
Storage Temperature	-30°C...+60°C
Contact Tab	Midget Groove
Wavelength (nm)	525
Intensity	1610mcd