




Electrical Commercial and Industrial

- Products
- Documentation & Literature
- News & Tradeshows
- Support

[United States](#) > [All 3M Products](#) > [Market Segments](#) > [Electronics, Electrical, and Communications](#) > [Electrical Products](#) > [Electrical Commercial and Industrial](#) > [Products](#) > _____

3M™ Scotchlok™ Butt Connector Nylon Insulated Grease Filled, 100/bottle, MNG18BCM-A

3M ID 80611466394 UPC# 00051128589939 3M Product Number MNG18BCM-A

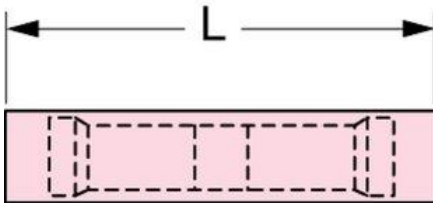

Butt Connector Nylon Insulated Grease Filled, 100/bottle, MNG18BCM-A

- Overview
- Documentation

Specifications

Barrel Inside Diameter	0.070 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Scotchlok
Conductor Sizes	22 - 18 AWG
Insulation Material	Nylon with Insulation Grip
Length (L)	1.02 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	100 per bottle
Terminal Style	Moisture Resistant
Terminal Type	Butt
Thickness	0.030 Inch