


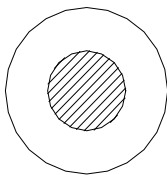

Product Name:	UL1180 28AWG
Product Discription:	UL1180 28AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		300Vac(UL allows 600V for electronic use only).			Conductor		Stranded Sliver plated copper					
Rated Temperature:		200℃,Optional - 80 ℃ Oil, Gasoline Resistant.			Size(AWG)		28					
Reference Standard:		UL758			Construction(±0.008mm)		7/0.127					
Cross Section					Stranded Dia.(mm)Ref.		0.38					
					Insulation Material		PTFE					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.33					
					Insulation Dia.(±0.08mm)		1.14					
Marking					Remark:							
No marking on the cable jacket, have UL label on the Reel.					8740135 Red		8740144 Blue		8740157 Grey		8740166 Violet	
					8740138 Black		8740147 White		8740150 Yellow			
					8740131 Brown		8740141 Green		8740153 Orange			
Applications					Characteristics					Customer Approve		
For internal wiring of electronic and electrical equipment					Test Item			Standard Value			Seal & Stamp	
					Test Material			PTFE(ROHS)				
					Insulation resistance(20℃ MΩ*m			1000				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)			203(MAX)			Signature: Date:	
Version	Description	Drawn by	Approved by	Date								
0	New document issue	Danniel	Jason	24/04/2015								