

ToLEDo Candle

ToLEDo Candle Dim Clear 470LM E14 SL

0026928



Range features

- Up to 88% energy saving compared to incandescent lamps
- Instant light
- 100% retrofit - Same dimensions as incandescent equivalent
- Suitable for replacement of up to 25W and 40W incandescent lamps
- Uniform light distribution
- Available in Homelight (2700K)
- Good colour rendering (CRI 80+)
- Average rated life 25,000 hrs

CE

PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026928
Average life (Rated) (h)	25000
Energy class	A+
Lamp shape	Candle
Lamp finish	Clear
Dimmable	Yes
Cap/Base	E14
Type	ToLEDo Candle
EAN code	5410288269283
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	470
Watt (Nominal) (W)	6.5
Equivalent watt (W)	40
Voltage (V)	220-240

ToLEDo Candle

ToLEDo Candle Dim Clear 470LM E14 SL

0026928

DATA TABLE

General data

Dry applications use only	Yes
Ordering number	0026928
Technology	LED
Energy saving lamp	Yes
Average life (Nominal) (h)	25000
Average life (Rated) (h)	25000
Energy class	A+
Lamp finish	Clear
Lamp shape	Candle
Dimmable	Yes
Cap/Base	E14
Type	ToLEDo Candle
EAN code	5410288269283
Long description	Up to 88% energy saving compared to incandescent lamps. Instant light. 100% retrofit - Same dimensions as incandescent equivalent. Suitable for replacement of up to 25W and 40W incandescent lamps. Uniform light distribution. Available in Homelight (2700K). Good colour rendering (CRI 80+). Average rated life 25,000 hrs
Product name	ToLEDo Candle Dim Clear 470LM E14 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Intended purpose	No
No. of switching cycles before premature failure (min)	50000
Special purpose lamp	No
Sales pack quantity	6
Optimal operating condition (°C)	25

Optical data

Light colour	Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	470
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	470

ToLEDo Candle

ToLEDo Candle Dim Clear 470LM E14 SL

0026928

Electrical data

kWh per 1000 hours burning time	7
Watt (Rated) (W)	6.5
Watt (Nominal) (W)	6.5
Equivalent watt (W)	40
Voltage (V)	220-240
Lamp power factor	0.55

Physical data


Weight (kg)	0.09
Lamp Length (mm) - C/L	112
Max. Lamp Diameter (mm) - D	38
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	12.60 x 4.80 x 4.80
Inner package dimensions (L x W x H) (cm)	15.50 x 10.50 x 14.10
Inner package net weight (kg)	0.51
Outer package dimensions (L x W x H) (cm)	55.00 x 32.60 x 16.10

ToLEDo Candle

ToLEDo Candle Dim Clear 470LM E14 SL

0026928

TECHNICAL DRAWINGS

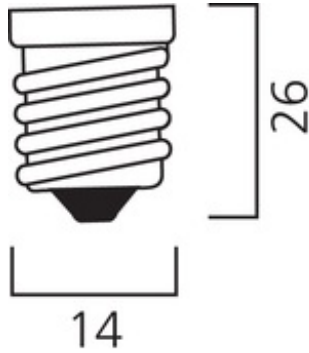

ENERGY LABEL

