



Capsuleline

Capsuleline 10W G4 12V CL 4000h 1CT

Single-ended low-voltage halogen capsule giving crisp white halogen light

Product data

• General Characteristics

Philips Code	13284
Cap-Base	G4
Cap-Base Information	na [-]
Bulb	T3 [T3: .354 inch / 9 mm]
Bulb Finish	Clear
Burning Position	any [Any/Universal]
Nominal Lifetime	4000 hr
Rated Lifetime	4000 hr
Rated Lifetime (years)	4 an

• Light Technical Characteristics

Colour Rendering Index	100 Ra8
Colour Temperature	2850 K
Colour Temperature Technical	2850 K
Lamp Luminous Flux	140 Lm
Rated Luminous Flux	140 Lm
Lamp Luminous Efficacy	14 Lm/W
LLMF - end nominal lifetime	80 (min) %

• Electrical Characteristics

Rated Wattage	10.0 W
Lamp Wattage	10 W
Technical Lamp Power	10.0 W
Power Factor	1 -
Voltage	12 V
Lamp Current	0.83 A
Dimmable	yes
Starting Time	0.0 s

Warm-up Time to 60% Light Outp instant full light

• Environmental Characteristics

Energy Efficiency Label (EEL)	C
Energy consumption kWh/1000h	11 kWh

• Measuring Conditions

Switching cycle	16000X
-----------------	--------

• Luminaire Design Requirements

Pinch Temperature	400 (max) C
Bulb Temperature	900 (max) C

• Product Dimensions

Overall Length C	33 (max) mm
Diameter D	9 (max) mm
Light Center Length L	22 mm

• Product Data

Order code	409706 50
Full product code	871150040970650
Full product name	Capsuleline 10W G4 12V CL 4000h 1CT
Order product name	Caps 10W G4 12V CL 4000h 1CT/ 10X10F
Pieces per pack	1
Packing configuration	10X10F
Packs per outerbox	100


PHILIPS

Capsuleline

Bar code on pack - EAN1 8711500409706
Bar code on intermediate packing - EAN2 8711500422132
Bar code on outerbox - EAN3 8711500425645


Logistic code(s) - 12NC 924036317101
ILCOS code HSG/C/UB-10-12-G4
Net weight per piece 1.200 gr

Dimensional drawing

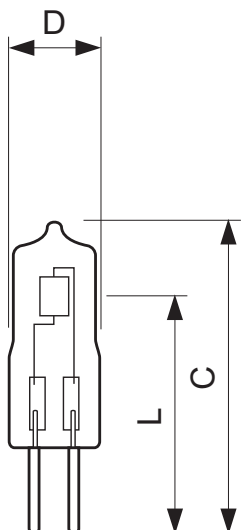

Capsuleline 10W G4 12V CL 4000h 1CT

Product	C (Max)	D (Max)	L (Norm)
CAP SU 13284 10W G4 12V CL	33	9	22

 

G4



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, April 17
data subject to change