


Datasheet

RS 3 Core Unscreened Industrial Cable, PVC Sheath, 440 V, 3.8mm OD, 0.22 mm² CSA 1 A, 25m

Stock Number - 660-4030

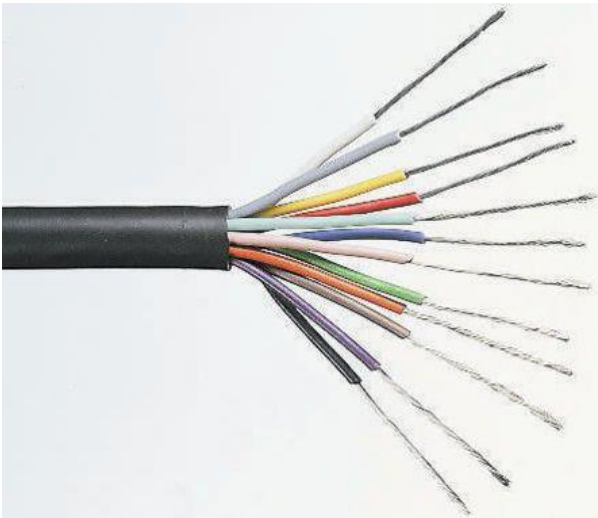

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):440

Flammability Test: IEC60332-1

Standard :

Manufacture to Def. Stan 61.12 Part 4 & 5



ENGLISH

Construction:

Conductor: Tinned Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 7$

Insulation: PVC

Insulation Dia. (mm): $1.2 \pm 0.05 \times 3C$

Tape: Mylar Spiral

Coverage: $\geq 115\%$

ID Thread : Green, White/Green

A rip cord : 210 D

Jacket: FR-PVC

Outer Dia. (mm): 3.6 ± 0.1

Colour:

The colour of the insulation: Red , Blue
, Green

The jacket colour: Black

Marking(3times/m):

RS 6604030 7 - 2 – 3A

Electrical Characteristics:**Max.Conductor DC Resistance at 20°C (Ω /Km) :**

<92

Min.Insulation DC Resistance at 20°C ($M\Omega$ *KM) :

>200

Current Rating : 1 A