


Deep groove ball bearings, single row, low-friction seal on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
20	32	7	4,03	2,32	0,104	45000	22000	0,018	61804-2RZ

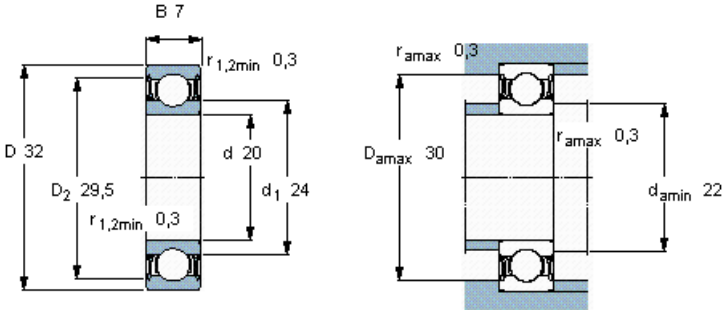

Calculation factors

$k_r = 0,015$

$f_0 = 15$