


**52601-S10-8LF - Quickie® : Double Row,
10 Positions, 2.54 mm (0.1 in.), SMT Header
0.38 µm (15 µin.) Gold Mating Plating**

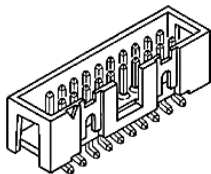

www.fci.com

Specifications

Approvals / Certifications

UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved

Electrical

Current rating	3 amp Continuous
Resistance (Insulation)	10000 M-ohms min.
Voltage rating	500V AC rms min.

General

Number of contacts (Total)	10
Number of rows	2
Orientation	SMT
Attachment type (Board)	Through Mount
Mating half	All Quickie® Receptacles. Select Discrete Wiring Mini-Latch Housings.

Mounting

Solder process	Wave Vapor-Phase IR Reflow
-----------------------	----------------------------------

Other Features

Packaging (Type)	Trays
Type	Low Profile

Physical

Color (Housing)	Black
Material (Contact)	Copper Alloy
Material (Housing)	High Temperature Thermoplastic
Plating (Contact area)	0.38 µm (15 µin.) Gold
Plating (Tail)	2.54 µm (100 µin.) Pure Tin
Underplating (Contact)	1.27 µm (50 µin.) Nickel
Flammability rating	UL 94V-0
Temperature (Range)	-65°C to +125°C