


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301990080](#)
Status: **Active**
Overview: [MAX-LOC® Plus Shielded Cord Grip Assemblies](#)
Description: Woodhead MAX-LOC Plus Shielded Cord-Grip Assembly, 3/0 AWG Cable with Black HNBR O-Ring and Grommet

Documents:

3D Model	Packaging Specification PK-130199-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-130199-001-001 (PDF)	Product Literature (PDF)
Application Specification AS-130199-002-001 (PDF)	

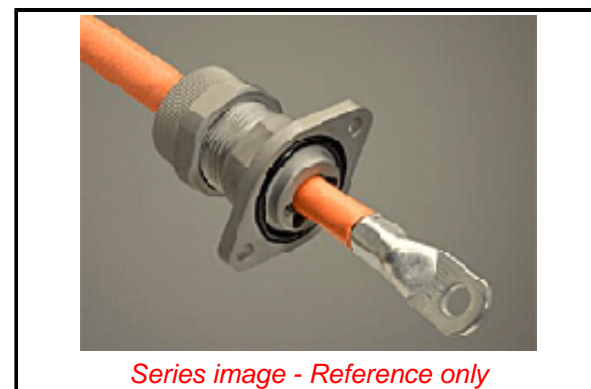

Series image - Reference only

General

Product Family	Cable Grips
Series	130199
Eye Type	N/A
O-Ring	Yes
Overview	MAX-LOC® Plus Shielded Cord Grip Assemblies
Product Literature Order No	987650-7321
Product Name	MAX-LOC
Type	MAX-LOC Connector
UPC	887191306230
Woodhead	Yes

Physical

Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	14.86-18.03mm (.585-.710")
Color - Grommet	Black
Gender	Female
Material - Body	Aluminum
Material - Grip	N/A
Mesh Length	N/A
Number of Holes	N/A
Thread Size	N/A

Material Info

Reference - Drawing Numbers

Application Specification	AS-130199-002-001
Packaging Specification	PK-130199-001
Product Specification	PS-130199-001-001
Sales Drawing	SD-130199-005

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130199 Series](#)