

Housing - HC-EVO-B24-SHWSC-2SSM40-PLRBK - 1407664

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Why buy this product

- Lower costs than metal version
- Low weight
- Lower risk of condensation
- Both contact insert PE sheets are connected by means of a metal frame integrated in the sleeve housing
- Metal inlays ensure leading PE contact with angled plugs
- Completely corrosion-resistant
- Halogen-free plastic
- Impact test according to IK 08



Key commercial data

Packing unit	1 pc
GTIN	 4 046356 777278
Weight per Piece (excluding packing)	255.5 g
Custom tariff number	85389099
Country of origin	Poland

Technical data

Dimensions

Height	84 mm
Width	57 mm
Length	144 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
Degree of protection of housing (NEMA)	4 (UL50e / NEMA 250)
	4X (UL50e / NEMA 250)

Housing - HC-EVO-B24-SHWSC-2SSM40-PLRBK - 1407664

Technical data

Ambient conditions

	12 (UL50e / NEMA 250)
	UL50e / NEMA 250
Ambient temperature (operation)	-40 °C ... 125 °C

General

Note	For contact inserts HC-B24, BB46, D64, DD108, M, K, HV10-I-PT, HV10-E...C
Type	B24
Housing type	Box mounting bases
Color	black
Locking type	With single locking latch
No. of cable outlets	2
Cable exit	Lateral
Screw connection	none
Type of the screw connection	2x M40
Protective cover	Yes
Housing material	Polyamide
Seal material	NBR
Material lock	Polyamide
Material, protective cover	Polyamide
Inflammability class according to UL 94	V0
Connection	One of the two openings for the screw connections is sealed but can be broken open using a screwdriver.

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440202

ETIM

ETIM 3.0	EC000437
ETIM 4.0	EC000437
ETIM 5.0	EC000437

UNSPSC

UNSPSC 6.01	31261502
-------------	----------

Housing - HC-EVO-B24-SHWSC-2SSM40-PLRBK - 1407664

Classifications

UNSPSC

UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

Approvals

Approvals

Approvals

GL / EAC

Ex Approvals

Approvals submitted

Approval details

GL

EAC

Accessories

Accessories

Full screw connection

Cable gland - HC-K-KV-M40(16-28)BK - 1407674



Plastic screw connection up to 5 bar, thread length: 10 mm, cable diameter: 16 - 28 mm, WAF 46, screw connection: M40

Housing latches

Housing - HC-EVO-B24-SHWSC-2SSM40-PLRBK - 1407664

Accessories

Single locking latch - HC-B24-SL-PLBK - 1407701



Replacement single locking latch for HEAVYCON EVO housing type B24, PA

Plug for cable screw gland

Filler plugs - HC-K-BS-M40-BK - 1410767



Filler plug, plastic, size: M40

Seal

Profile gasket - HC-B24-SP-RBK - 1407709



Profile gasket for HEAVYCON EVO supporting base element type B24

Protective covers - HC-B24-BC-HI-PLBK - 1407695




HEAVYCON EVO hinged protective cover, type B24, for EVO supporting base element, IP65, PA

Drawings

Housing - HC-EVO-B24-SHWSC-2SSM40-PLRBK - 1407664

Dimensioned drawing

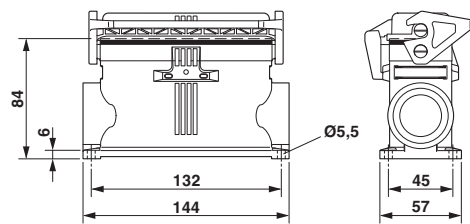

Dimensional drawing