

## ECO SST CL P 30 W 240 V E14

CLASSIC ECO SUPERSTAR P | Halogen lamps, classic mini-ball shape



### Areas of application

- General illumination
- Mood lighting
- Entrance lighting
- Mirror lighting

### Product benefits

- Simple direct replacement for conventional incandescent lamps
- The same pleasant quality of light as that of an incandescent lamp
- Instant 100 % light, no warm-up time
- Contains no mercury
- UV filter

### Product features

- Average life: 2,000 h
- 100 % dimmable
- Perfect color rendering ( $R_a : 100$ )



## Product datasheet

---

### Technical data

---

#### Electrical data

Nominal wattage	30.00 W
Nominal voltage	240 V
Rated wattage	30.00 W
Claimed equiv. conventional lamp power	40 W
Power factor $\lambda$	1.00
Energy consumption	30 kWh/1000h

#### Photometrical data


Nominal luminous flux	405 lm
Color temperature	2700 K
Light color as per EN 12464-1	Warm White
Rated luminous flux	405 lm
Color rendering index Ra	100
Lumen main.fact.at end of nom.life time	0.80

#### Light technical data

Starting time	0.0 s
Warm-up time (60 %)	0.00 s

#### Dimensions & weight

---

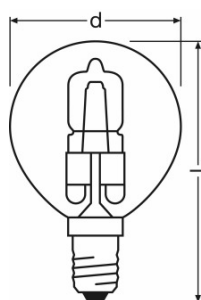

---

#### Product line drawing

Diameter	45.0 mm
Overall length	77.0 mm
Length	77.0 mm

## Product datasheet

Light center length (LCL)	60.0 mm
Outer bulb	P45

### Colors & materials


Lamp mercury content	0.0 mg
Mercury-free	Yes

### Lifespan

Nominal lamp life time	2000 h
Rated lamp life time	2000 h
Number of switching cycles	50000 <sup>1)</sup>

<sup>1)</sup> At 1 min on / 3 min off

### Additional product data

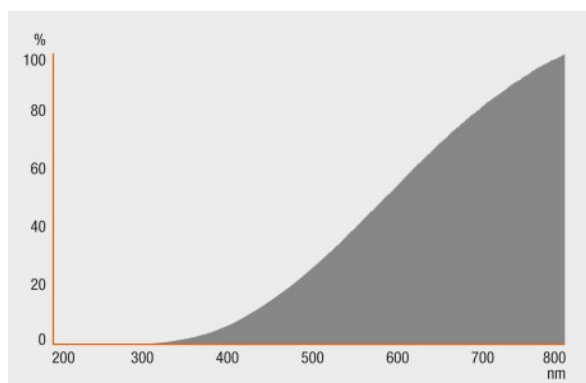

### Spectral power distribution

Base (standard designation)	E14
-----------------------------	-----

### Capabilities

Burning position	Any
Dimmable	Yes

### Certificates & standards

## Product datasheet

<b>Energy efficiency class</b>	D
--------------------------------	---

### Country specific categorizations

<b>ILCOS</b>	HSGSP/C/UB-30-240-E14-60
<b>Order reference</b>	64542 P ECO 30W

---

### Country specific information

<b>Product code</b>	<b>METEL-Code</b>	<b>SEG-No.</b>	<b>STK number</b>	<b>UK Org</b>
4008321952851	-	-	4730007	-

## Product datasheet

---

### Logistical Data

---

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321952837	ECO SST CL P 30 W 240 V E14	Blister 1	94 mm x 7 mm x 140 mm	0.09 dm <sup>3</sup>	25.50 g
4008321952844	ECO SST CL P 30 W 240 V E14	Shipping carton box 10	135 mm x 155 mm x 314 mm	6.57 dm <sup>3</sup>	394.93 g
4008321952851	ECO SST CL P 30 W 240 V E14	Folding carton box 1	46 mm x 46 mm x 77 mm	0.16 dm <sup>3</sup>	22.60 g
4008321952868	ECO SST CL P 30 W 240 V E14	Shipping carton box 20	193 mm x 85 mm x 235 mm	3.86 dm <sup>3</sup>	562.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

---

### Disclaimer

---

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.