


Datasheet

Steel Zinc Plated Toggle Latch, 250kgf Op. Tension

RS Stock number [206-4589](#)

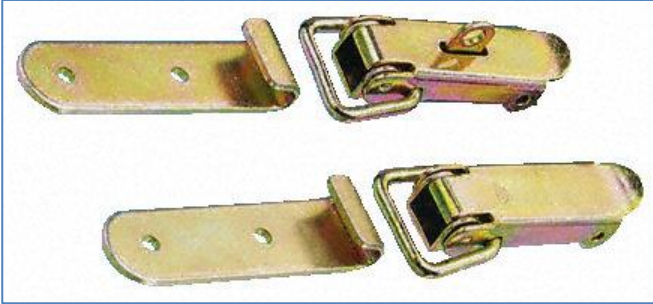

Description:

This design is particularly recommended for equipment liable to vibration. A sprung catch fitted to the inside wall locks the toggle arm down making accidental release difficult. A wedged blade such as a small screw driver should be used to open the spring safety lock.

Suitable for screw fixing using 4 M5 screws

Holes provided for tamper sealing

Padlock option available

Features:

- Dimensions 86 x 40 x 22mm
- Finish Zinc Plated
- Lockable Yes, Lock Not Included
- Material Steel
- Operating Tension 250kgf
- Spring Loaded Yes

