

**EX-STOCK 3 DAY DELIVERY FREE OF CHARGE (UK)**  
**For Fast Friendly Service and Competitive Pricing Contact Us Now**

**IBIZA**

IP-55 wall mounting, powder coated RAL7032 steel enclosures.  
 Reversible door fitting for left or right hand opening.  
 DIN double bar locks supplied as standard.  
 Internal door mounting accessory profile as standard from 500x400mm.  
 Large single entry plate equals Width less 45mm and Depth less 70mm.  
 Mounting plate fitting supplied with enclosure.




Type	H x W x Dmm	Type	H x W x Dmm	Steel Mounting Plates
IB-2520/150	250x200x150	IB-54/200	500x400x200	IBPM-2520
IB-3025/150	300x250x150	IB-54/250	500x400x250	IBPM-3025
IB-33/150	300x300x150	IB-64/200	600x400x200	IBPM-33
IB-33/200	300x300x200	IB-64/250	600x400x250	IBPM-34
IB-34/200	300x400x200	IB-65/200	600x500x200	IBPM-44
IB-43/150	400x300x150	IB-66/250	600x600x250	IBPM-54
IB-43/200	400x300x200	IB-75/250	700x500x250	IBPM-64
IB-44/150	400x400x150	IB-86/250	800x600x250	IBPM-65
IB-44/200	400x400x200	IB-86/300	800x600x300	IBPM-66
IB-54/150	500x400x150	IB-108/300	1000x800x300	IBPM-75
		Other sizes available		IBPM-86
				IBPM-108

External Mounting Brackets - IBPF

Metal Barrel Key Lock - IB-CLL

**MINIPOL**

IP-65 wall mounting GRP moulded enclosures.  
 Colour RAL 9002.  
 Supplied standard with DIN double bar locks and external mounting brackets.  
 Options of plain or glazed door.

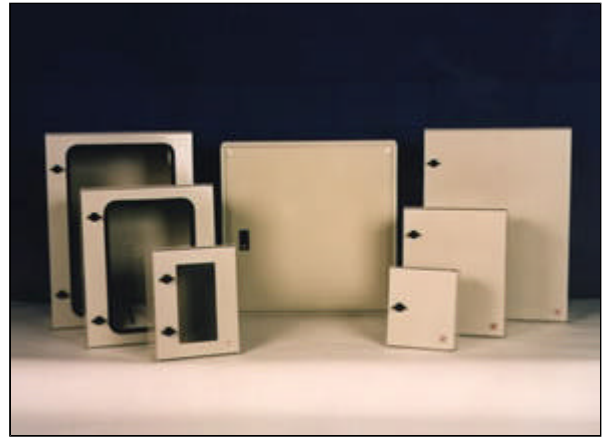

**With plain door**

Type	H x W x Dmm
MIP-325	300x250x140
MIP-43	400x300x200
MIP-44	400x400x200
MIP-54	500x400x200
MIP-64	600x400x230
MIP-65	600x500x230
MIP-86	800x600x300

**With window door**

Type	H x W x Dmm
MIP-325PT	300x250x140
MIP-43PT	400x300x200
MIP-44PT	400x400x200
MIP-54PT	500x400x200
MIP-64PT	600x400x230
MIP-65PT	600x500x230
MIP-86PT	800x600x300

**Mounting plates**

Metal	GRP
PBM-325/B	PBP-325
PBM-43/B	PBP-43
PBM-44/B	PBP-44
PBM-54/B	PBP-54
PBM-64/B	PBP-64
PBM-65/B	PBP-65
PBM-86/B	PBP-86

Accessories available:

-----