

Datasheet

RS Pro P13.5s Filament Indicator Lamp, Clear, 5.2 V, 500 mA, 15h

RS Stock No: **105-180**



Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton and Xenon gas for super-high brightness. It has a voltage rating of 5.2 V and current rating of 500 mA. The lamp has 15 h life.

Features and Benefits


- Alternative to vacuum types
- P13.5s prefocus base
- Clear lens



Specifications:

Current Rating	500 mA
Diameter	9.3 mm
Lamp Base	P13.5s
Lamp Size	T9
Length	31 mm
Lens Colour	Clear
Life Hours	15 h
Luminosity	48 lm
Voltage Rating	5.2 V

DRAWING - I

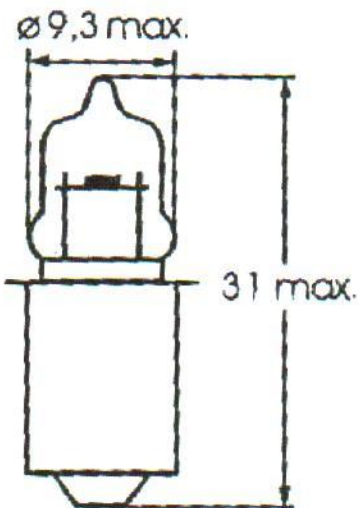

Unit : mm

1. Structure	Bulb Type	T9x28
	Bulb Diameter	Ø 9.3Max
	Length	31.0Max
	Base Type	P13.5s
2. Design Characteristics	Voltage	5.2V
	Amperage	500mA±10%
	Gas Type	Halogen gas-filled
	M.S.C.P.	3.81CP±20%
	Life Hours	15Hrs