



ECR Union Cross For fractional tube

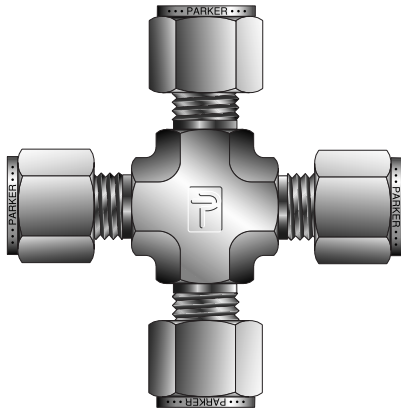


PARKER PART NO.	INTER- CHANGES WITH	INCHES				
		TUBE O.D.	A	C	L	W HEX
2ECR2	200-4	1/8	1.84	.92	.66	7/16
3ECR3	300-4	3/16	1.92	.95	.69	7/16
4ECR4	400-4	1/4	2.02	1.01	.72	7/16
5ECR5	500-4	5/16	2.28	1.14	.84	9/16
6ECR6	600-4	3/8	2.26	1.13	.84	9/16
8ECR8	810-4	1/2	2.74	1.37	.97	3/4
10ECR10	1010-4	5/8	2.86	1.43	1.03	1-1/16
12ECR12	1210-4	3/4	3.12	1.56	1.16	1-1/16
14ECR14	1410-4	7/8	3.52	1.76	1.36	1-5/16
16ECR16	1610-4	1	3.86	1.93	1.45	1-5/16

NOTE: A and C dimensions are typical finger-tight.

Dimensions for reference only, subject to change.

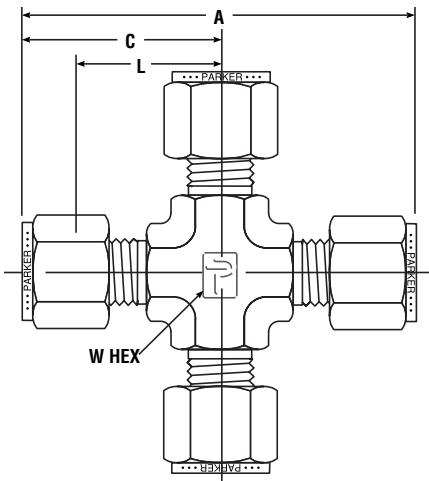

ECRM Union Cross For metric tube

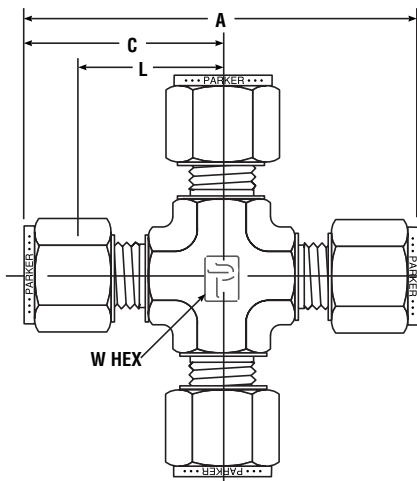

PARKER PART NO.	INTER- CHANGES WITH	MILLIMETERS				INCH
		TUBE O.D.	A	C	L	W HEX
ECRM3	3MO-4	3	44,7	22,3	15,7	7/16
ECRM4	4MO-4	4	50,8	25,4	18,8	1/2
ECRM6	6MO-4	6	53,9	27,0	19,6	1/2
ECRM8	8MO-4	8	59,7	29,9	22,4	5/8
ECRM10	10MO-4	10	67,0	33,5	25,9	13/16
ECRM12	12MO-4	12	72,0	36,0	25,9	13/16
ECRM16	16MO-4	16	74,0	37,0	26,9	15/16
ECRM18	18MO-4	18	76,6	38,3	28,2	1-1/16

NOTE: A and C dimensions are typical finger-tight.

Dimensions for reference only, subject to change.