



PORTABLE LIGHTING FOR PROFESSIONALS

Torches/Flashlights LED Torches



PERSONAL LIGHTING



X21 Torch



P5 Torch



P7 Torch



K3 Torch

P3 Torch

- PERFORMANCE:** Extremely powerful and professional specifications. The X21 is the brightest hand held LED Torch ever produced!
- DURABLE:** All metal construction. Sealed design.
- VERSATILE:** Unique Hi-Speed Focus adapts to all situations.
- ADVANCED:** Microprocessor power controller maximises efficiency and battery life.
- ADJUSTABLE:** Single touch Hi-Speed switch for brightness control. Includes 'Turbo-Mode' for defensive use.
- QUALITY:** Maximum specification LED's and Gold Contacts for ultimate long-term performance.

..

Order Codes: See overleaf

TECHNICAL DATA

Torches Flashlights LED Torches

- The highest performance and most versatile LED hand held Torches available. The X21 and X21R are the most powerful models ever produced.
- Superb and unique optical design enables hi-speed 'one-touch' focusing for optimum close, medium and long range applications.
- Dynamic electronic light output control offers lightning fast selection of various power levels including 'Turbo Boost' for defensive and personal protection situations.
- All metal aerospace grade aluminium construction and sealed design for long term use under demanding professional conditions.
- Microprocessor power and voltage control maximises light output, efficiency and operating time.
- Rechargeable versions include charging cradle and durable hard plastic case

Model	Light Output	Duration Hours	Power Source	Focusing	Power Control	Dimensions mm	Weight gms	Colour
P5	90 Lumens 130 Metres	3	1 x AA	Spot/ Flood	No	124 x 25	84	Black/Titanium
P7	200 Lumens 220 Metres	64	4 x AAA	Spot/ Flood	Yes	135 x 37	196	Black/Titanium
T7	200 Lumens 220 Metres	64	4 x AAA	Spot/ Flood	Yes	137 x 37	192	Black
X21	950 Lumens 535 Metres	244	4 x D	Spot/ Flood	Yes	400 x 195	1440	Black
Police Tech Focus	105 Lumens 200 Metres	50	3 x AAA	Spot/ Flood	No	129 x 32	144	Black/Titanium/ Cobalt Blue
P5R	210 Lumens 175 Metres	7	Rechargeable	Spot/ Flood	Yes	105 x 26	180	Black
X21R	1270 Lumens 750 Metres	100	Rechargeable	Spot/ Flood	Yes	400 x 195	1440	Black


Key Ring Torches

K3	14 Lumens 30 Metres	50	4 x AG13	Spot/ Flood	No	68 x 20	34	Black/Titanium
P3	16 Lumens 31 Metres	6	1 x AAA	Spot/ Flood	No	94 x 20	42	Black/Titanium

General Purpose LED Torch

A very cost effective LED Torch designed for general use. Tough plastic waterproof construction featuring rubberised lens and end cap protection. Anti-roll design with integral metal hanging hook

LED Torch	25 hours 40 Metres	200	4 x AA	Fixed Focus	No	130 x 60	232	Yellow
-----------	--------------------	-----	--------	-------------	----	----------	-----	--------

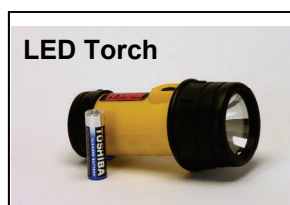

ATEX - For Hazardous Area Torches and Floodlights please see ATEX section ON our website.

Accessories available - please see website or ring our sales office for details.