


HC-A3-BUQ1,5-TFL-G-PA

Order No.: 1641510



HEAVYCON QUICKON sleeve housing A3, for single locking latch, 3-pos., with PE connection, socket, QUICKON connection, straight cable outlet

| Commercial data | |
|--------------------------|--|
| GTIN (EAN) |  4 017918 889920 |
| sales group | D442 |
| Pack | 1 pcs. |
| Customs tariff | 85369010 |
| Catalog page information | Page 507 (PC-2011) |

Product notes

WEEE/RoHS-compliant since:
08/01/2005



<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

| Technical data | |
|--------------------------------|---|
| General characteristics | |
| Connection | If the conductor is reconnected, it must be cut off above the last contact point. QUICKON components may only be operated when under no load. |
| Type | Female |
| Design | D7 |

| | |
|--|--------------------------|
| Housing type | Sleeve housings |
| Locking type | for single locking latch |
| Connection method | QUICKON connection |
| Number of positions | 3 |
| Wrench size, union nut | 19 mm |
| Tightening torque, union nut | 3 Nm |
| Conductor cross section stranded min. | 0.75 mm ² |
| Conductor cross section stranded max. | 1.5 mm ² |
| Conductor cross section AWG/kcmil min. | 18 |
| Conductor cross section AWG/kcmil max | 16 |

Conductor data

| | |
|---|--|
| Structure of individual litz in acc. with VDE 0295 / smallest wire diameter | VDE 0295 Cl.2-5, min. wire diameter 0.2 mm |
| Wire insulation material | PVC/PE |
| Wire diameter including insulation | 1.8 mm ... 3 mm |
| External cable diameter | 6 mm ... 12 mm |

Environmental conditions

| | |
|---|--|
| Degree of protection | IP65 |
| Ambient temperature (operation) | -25 °C ... 80 °C |
| Ambient temperature (storage/transport) | -25 °C ... 80 °C |
| Temperature when conductor connected | -5 °C ... 50 °C (specifications of the cable manufacturer must also be observed) |

Electrical characteristics

| | |
|-----------------------------------|-------------|
| Rated current | 10 A |
| Note on the rated voltage (III/3) | 250 / 400 V |
| Rated voltage (III/2) | 630 V |
| Rated voltage (II/2) | 1000 V |
| Rated surge voltage (III/3) | 4 kV |
| Rated surge voltage (III/2) | 4 kV |
| Rated surge voltage (II/2) | 4 kV |

Mechanical characteristics

| | |
|-----------------------------|---|
| QUICKON connectability | 10 (For the same conductor cross section) |
| Insertion/withdrawal cycles | 500 |

Material data

| | |
|------------------------------------|---------------|
| Contact material | Cu alloy |
| Contact surface material | Silver-plated |
| Contact carrier material | PA / PC |
| Insulating material | PA |
| Inflammability class acc. to UL 94 | V0 |
| Surge voltage category | III |
| Pollution degree | 3 |

Certificates / Approvals

Certification


CUL, GOST, UL

Accessories

| Item | Designation | Description |
|----------------|-----------------------------|--|
| General | | |
| 1642182 | Q 1,5/4IDC/24-24KU-KU BK PE | QUICKON cable connector, black, 3+PE-pos., 0.75 mm ² ... 1.5 mm ² /500 V/15 A, for a cable diameter of 6 mm ... 12 mm. |
| Tools | | |
| 1205862 | MICROFOX SC | Diagonal cutter for Cu wire up to 1.5 mm diameter |
| 1670895 | QSS 19 | Socket wrench, for tightening and unscrewing the QUICKON union nut, wrench size 19 mm |

Diagrams/Drawings

Diagram

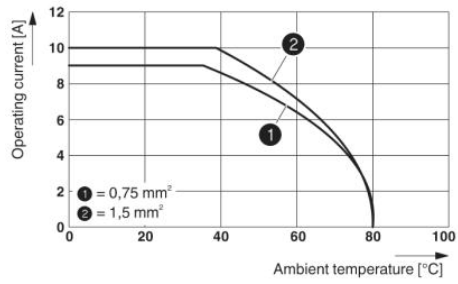

Derating diagram: HC-A3...Q1,5...

Dimensioned drawing

