
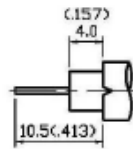


# Datasheet

## Straight Cable Mount F Connector / Crimp Termination

RS Stock number [546-2740](#)

Dimensions: (mm)

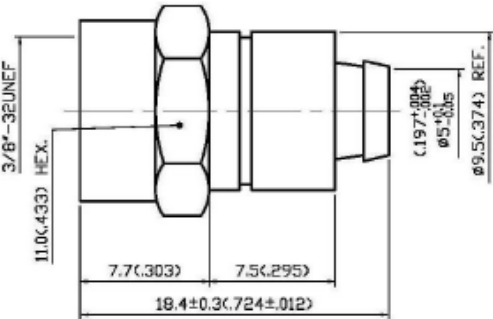

STRIPPING DIMENSION  
SCALE 2:1

### Specifications

Electrical	Materials	Mechanical	Environmental
<ul style="list-style-type: none"> <li>Frequency Range:DC-1 GHz</li> </ul>	<ul style="list-style-type: none"> <li>Bodies: Brass Per JIS-C3604</li> </ul>	<ul style="list-style-type: none"> <li>For use with 6U or similar style cable</li> <li>Cable attachment: outer crimp</li> <li>Crimp size required: Ferrule 8.2 Hex</li> </ul>	<ul style="list-style-type: none"> <li>Operating temperature: -40°C to +80°C</li> </ul>

No.	Description	Material	Finish
1	Nut	Brass	Nickel 100µ"Min
2	Body	Brass	Nickel 100µ"Min
3	Chassis	Brass	Nickel 100µ"Min