

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [90156-0143](#)
Status: **Active**
Overview: C-Grid III™
Description: 2.54mm Pitch C-Grid III™ Crimp Housing Single Row, 3 Circuits

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	Crimp Housings
Series	90156
Application	Signal, Wire-to-Board
MolexKits	Yes
Overview	C-Grid III™
Product Name	C-Grid III™
UPC	800753668140

Physical

Breakaway	No
Circuits (maximum)	3
Color - Resin	Black
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	PPO
Net Weight	0.293/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Temperature Range - Operating	-55°C to +105°C


Electrical

Current - Maximum per Contact	3A
-------------------------------	----

Material Info

Reference - Drawing Numbers

Sales Drawing	SDA-90156
---------------	-----------

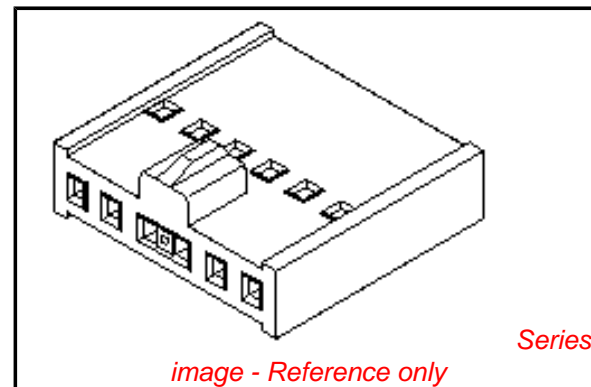

EU RoHS

ELV and RoHS Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[90156Series](#)

Mates With

[90120](#) , [90121](#) , [90136](#)

Use With

[90119](#)