

Base strip - MC 0,5/15-G-2,54 SMD R56 - 1821821

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)


Header, Nominal current: 6 A, Rated voltage (III/2): 160 V, Number of positions: 15, Pitch: 2.54 mm, Color: black, Contact surface: Gold, Mounting: Taped SMD/THT/THR components



The illustration shows the 10-position version



Key commercial data

| | |
|--------------------------------------|---|
| Packing unit | 465 pc |
| Minimum order quantity | 465 pc |
| GTIN |  4 046356 789981 |
| Weight per Piece (excluding packing) | 2.22 g |
| Custom tariff number | 85366990 |
| Country of origin | Germany |
| Note | Made to Order (non-returnable) |

Technical data

Dimensions

| | |
|----------------|----------------|
| Length | 7.1 mm |
| Height | 4.8 mm |
| Width | 42.64 mm |
| Pitch | 2.54 mm |
| Dimension a | 35.56 mm |
| Pin dimensions | 0,64 x 0,64 mm |

General

| | |
|-----------------------------|------------------|
| Range of articles | MC 0,5/...-G-SMD |
| Insulating material group | IIIa |
| Rated surge voltage (III/3) | 2.5 kV |
| Rated surge voltage (III/2) | 2.5 kV |
| Rated surge voltage (II/2) | 2.5 kV |
| Rated voltage (III/3) | 32 V |

Base strip - MC 0,5/15-G-2,54 SMD R56 - 1821821

Technical data

General

| | |
|---|--------|
| Rated voltage (III/2) | 160 V |
| Rated voltage (II/2) | 160 V |
| Connection in acc. with standard | EN-VDE |
| Nominal current I _N | 6 A |
| Insulating material | LCP |
| Inflammability class according to UL 94 | V0 |
| Color | black |
| Number of positions | 15 |

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.0 | 272607xx |
| eCl@ss 4.1 | 27260701 |
| eCl@ss 5.0 | 27260701 |
| eCl@ss 5.1 | 27260701 |
| eCl@ss 6.0 | 27260704 |
| eCl@ss 7.0 | 27440402 |
| eCl@ss 8.0 | 27440402 |

ETIM

| | |
|----------|----------|
| ETIM 3.0 | EC001121 |
| ETIM 4.0 | EC002637 |
| ETIM 5.0 | EC002637 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 30211810 |
| UNSPSC 7.0901 | 39121409 |
| UNSPSC 11 | 39121409 |
| UNSPSC 12.01 | 39121409 |
| UNSPSC 13.2 | 39121409 |

Accessories

Accessories

Labeled terminal marker

Base strip - MC 0,5/15-G-2,54 SMD R56 - 1821821

Accessories

Marker card - SK 2,54/2,8:FORTL.ZAHLEN - 0804853



Marker card, Card, white, labeled, Horizontal: Consecutive numbers 1 - 10, 11 - 20, etc. up to 91 - 99, Mounting type: Adhesive, for terminal block width: 2.54 mm, Lettering field: 2.54 x 2.8 mm

Additional products


Printed-circuit board connector - FMC 0,5/15-ST-2,54 - 1821229




Plug component, Nominal current: 6 A, Rated voltage (III/2): 160 V, Number of positions: 15, Pitch: 2.54 mm, Connection method: Spring-cage connection, Color: black, Contact surface: Gold

Drawings


Drilling diagram

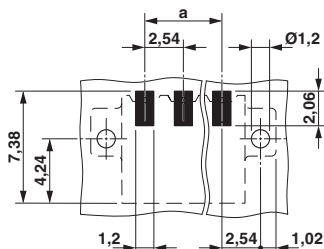

Dimensioned drawing

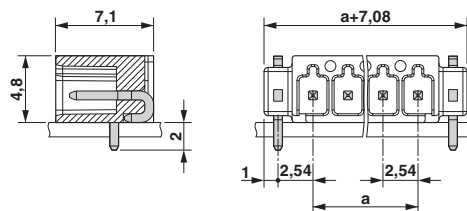

Diagram

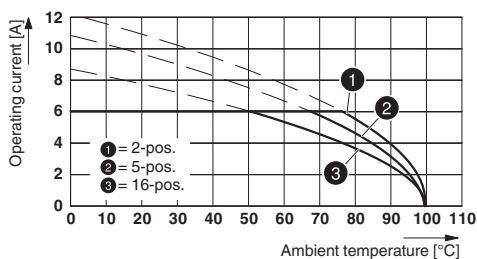

Type: FMC 0,5/...-ST-2,54 with MC 0,5/...-G-2,54 SMD R..