


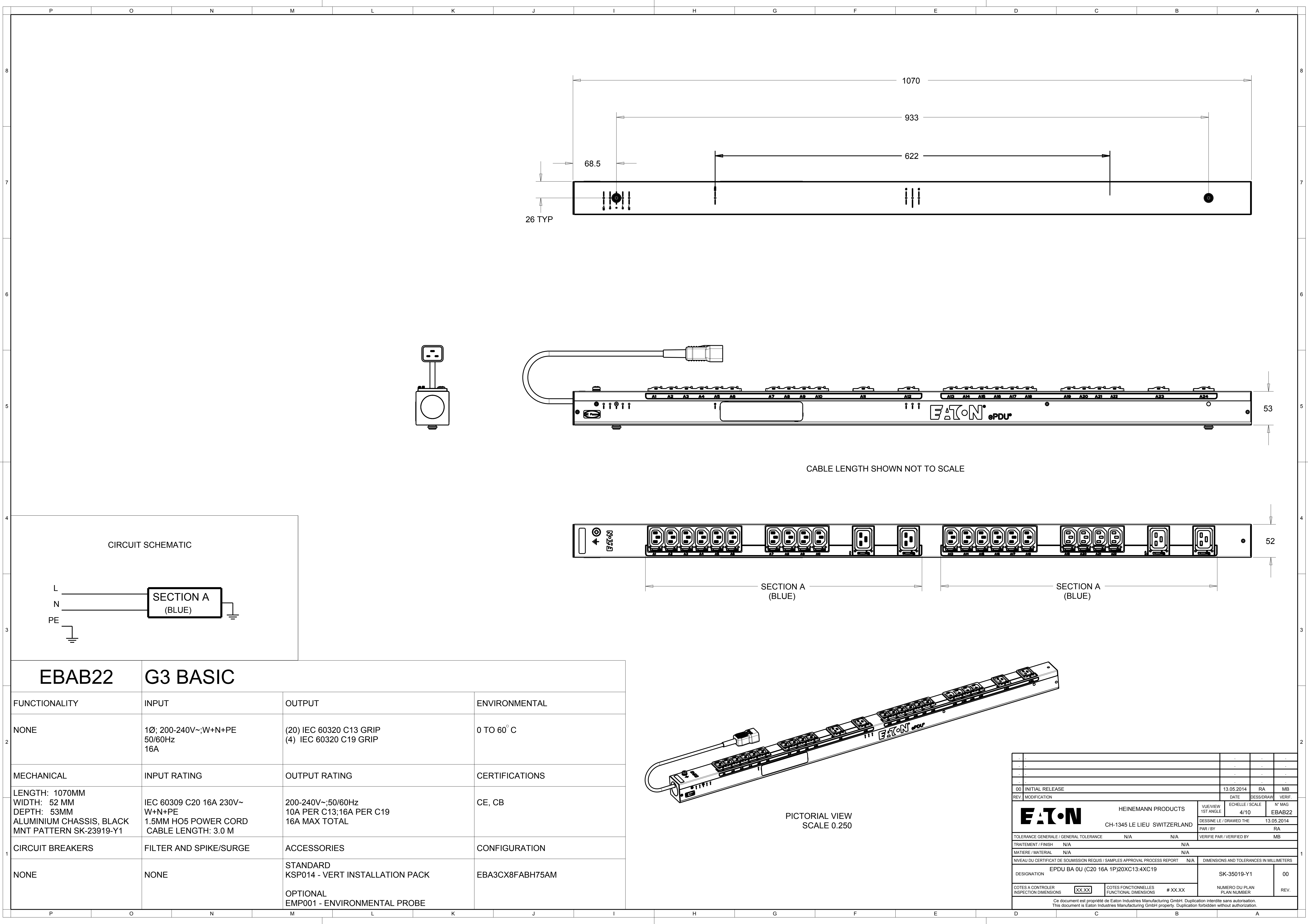

EBAB22		G3 BASIC	
FUNCTIONALITY	INPUT	OUTPUT	ENVIRONMENTAL
NONE	1Ø; 200-240V~;W+N+PE 50/60Hz 16A	(20) IEC 60320 C13 GRIP (4) IEC 60320 C19 GRIP	0 TO 60° C
MECHANICAL	INPUT RATING	OUTPUT RATING	CERTIFICATIONS
LENGTH: 1070MM WIDTH: 52 MM DEPTH: 53MM ALUMINIUM CHASSIS, BLACK MNT PATTERN SK-23919-Y1	IEC 60309 C20 16A 230V~ W+N+PE 1.5MM H05 POWER CORD CABLE LENGTH: 3.0 M	200-240V~;50/60Hz 10A PER C13;16A PER C19 16A MAX TOTAL	CE, CB
CIRCUIT BREAKERS	FILTER AND SPIKE/SURGE	ACCESSORIES	CONFIGURATION
NONE	NONE	STANDARD KSP014 - VERT INSTALLATION PACK OPTIONAL EMP001 - ENVIRONMENTAL PROBE	EBA3CX8FABH75AM

00	INITIAL RELEASE	13.05.2014	RA	MB
REV.	MODIFICATION	DATE	DESSIN/DRW	VERIF.
EAT•N		HEINEMANN PRODUCTS	VUE/VIEW 1ST ANGLE	N° MAG EBAB22
CH-1345 LE LIEU SWITZERLAND		DESSINE LE / DRAWED THE	13.05.2014	
TOLERANCE GENERALE / GENERAL TOLERANCE		N/A	N/A	VERIFIE PAR / VERIFIED BY
TRAITEMENT / FINISH		N/A	N/A	
MATIERE / MATERIAL		N/A	N/A	
NIVEAU DU CERTIFICAT DE SOUMISSION REQUIS / SAMPLES APPROVAL PROCESS REPORT		N/A	DIMENSIONS AND TOLERANCES IN MILLIMETERS	
DESIGNATION		EPDU BA 0U (C20 16A 1P)20XC13:4XC19		
COTES A CONTROLER INSPECTION DIMENSIONS		COTES FONCTIONNELLES FUNCTIONAL DIMENSIONS	# XX.XX	NUMERO DU PLAN PLAN NUMBER
Ce document est propriété de Eaton Industries Manufacturing GmbH. Duplication interdite sans autorisation. This document is Eaton Industries Manufacturing GmbH property. Duplication forbidden without authorization.				