

# M 221 G



Euromas  
 Enclosure, polycarbonate

**Order no.: 02221100**

**Colour of enclosure group**

Light grey, similar to RAL 7035; special colours on request

**Protection class**


Depending on the model: IP 65 or IP 66/DIN EN 60529; IP 67 available on request for some sizes.

**Enclosure material**

ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request), seal made of CR; for details see Technical Information

Scope of delivery: Lid and base, lid screws made of V2A, self-tapping screws for mounting bosses

Note: G = Design with crystal-clear lid.  
 IP = Ingress protection acc. to DIN EN 60529

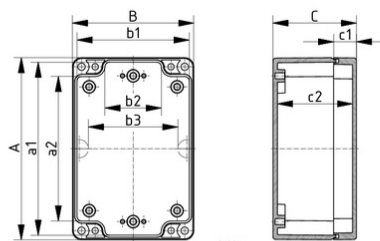

<b>A</b>	200 mm
<b>B</b>	120 mm
<b>C</b>	75 mm
<b>a1</b>	193 mm
<b>a2</b>	174,2 mm
<b>b1</b>	113 mm
<b>b2</b>	74,2 mm
<b>c1</b>	15 mm
<b>c2</b>	68,5 mm

**Technical drawings**

3D product data in STEP format:  
[Registration necessary](#)  
 Basic drawing for processing work:  
[02221100\\_M-221-G.dxf](#) (707 KB)  
 Basic drawing for processing work:  
[02221100\\_M-221-G-G.dxf](#) (354 KB)  
 Catalogue drawing in PDF format:  
[02221100\\_M-221-G.pdf](#) (95 KB)

**Chapter download**

[Euromas\\_ABS\\_PC\\_GB.pdf](#) (338 KB)

## Accessories



**Mounting plates, laminated paper (Pertinax), galvanised steel for version 260**

22000700

[M](#)

For EM/ET 221, EM/ET 237, M/T 221, M/T 237



**Knurled screws**

22003100

[RD](#)

For M/T 210-215, M/T 217, M/T 220-227, M/T 231



**Rubber feet, plug-in**

22003300

[F](#)

For M/T 208-260



**Silicone seal for lid**

22003900

[SIL](#)

For M/T 221, M/T 237



**Wall brackets on rear, screw-on, polycarbonate**

22004900

[WL](#)

For M/T 210-243, M/T 246-253



**DIN rails DIN EN 60715 TH 15**

22002100

[TS 15](#)

For M/T 221-223, M/T 237



**DIN rails DIN EN 60715 G 32**

22002110

[TS 32](#)


For M/T 221-223, M/T 237



**DIN rails DIN EN 60715 TH 35**

22002115 [TS 35](#)

For M/T 221-223, M/T 237

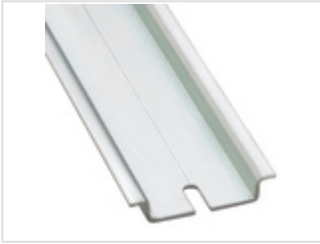

**Threaded inserts for mounting bosses**

59002810 [DODGE M3x6,5](#) ND = 4.0 x 6.5  
59002820 [DODGE M4x9,5](#) ND = 5.4 x 9.5



\* = Available on request