


LEDs & INDICATORS


509 M-LED Series

- Threaded body for panel thicknesses 0.5-2.5mm, panel cut-out 6.5mm diameter
- 3.2mm LED with pin termination, anode pin cut short
- Polycarbonate lens with 65° viewing angle
- Nickel plated brass body, supplied with nut and shakeproof washer
- Red, green and amber lenses colour options as standard
- Blue and clear lenses to order
- Maximum working temperature 80°C

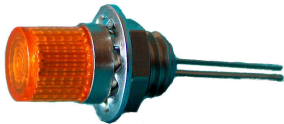


	TYPE NO.	509	X	13 -	LED	- T /	XXX
509 Series Indicator	509						
Lens cyclinder flat	1						
Lens cyclinder domed	2						
Pin termination	13						
LED, anode pin cut short	LED						
Transparent lens	T						
Lens colour Red	RED						
Lens colour Green	GRN						
Lens colour Amber	AMB						
Lens colour Blue	BLU						
Lens colour Clear	CLR						

Body Dimensions

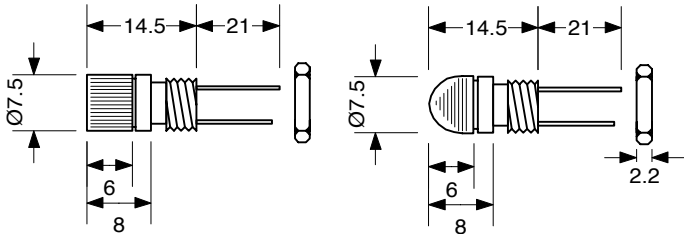

514 23-LED Series

 - Press-fit body for various panel thickness, panel cut-out 8.0mm diameter
- LED pin termination, anode pin cut short
- Polycarbonate body/bezel and lens
- Red, green, amber, and blue lens colour options as standard
- Maximum working temperature 105°C



	TYPE NO.	514	1	13 -	LED	- T /	XXX
515 Series Indicator	514						
Lens Type	1						
Pin termination	13						
LED, anode pin cut short	LED						
Transparent lens	T						
Lens colour Red	RED						
Lens colour Green	GRN						
Lens colour Amber	AMB						
Lens colour Blue	BLU						

Body Dimensions

