


DECORATIVE

SWITCHSOCKET OUTLETS RCD PROTECTED 13 AMP FLUSH

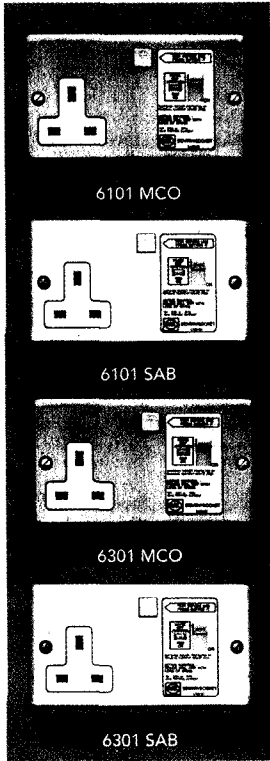

- 6101 MCO** 1
- 6101 SAB** 1
- 1 GANG
10mA RATED TRIPPING
CURRENT
ACTIVE CONTROL CIRCUIT
- 6301 MCO** 1
- 6301 SAB** 1
- 1 GANG
30mA RATED TRIPPING
CURRENT
ACTIVE CONTROL CIRCUIT

MOUNTING BOXES

FLUSH:
886 ZIC

SURFACE:
2002 ALM
2004 ALM

Boxes have a minimum depth
of 35mm

These products are a.c. and
pulsating d.c. fault current
sensitive and are suitable for
supply voltage of 240V a.c.
50Hz.


Further details regarding these
products can be found on
page 174

DIMENSIONS:
86 x 146mm

FIXING CENTRES:
120.6mm

BS.7288: 1990

ROUND PIN FLUSH

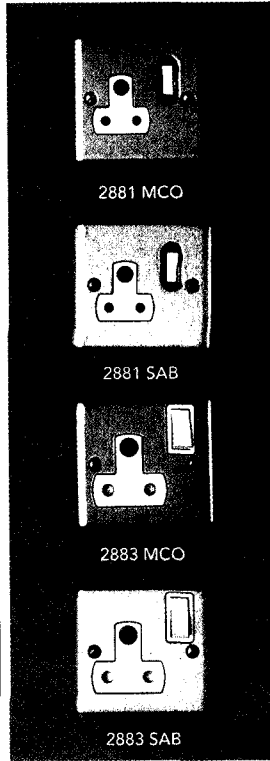

- 2881 MCO** 10
- 2881 SAB** 10
- 1 GANG
5 AMP
SHUTTERED
- 2883 MCO** 10
- 2883 SAB** 10
- 1 GANG
15 AMP
SHUTTERED

MOUNTING BOXES

FLUSH:
866 ZIC

SURFACE:
2001 ALM
2003 ALM

Boxes have a minimum depth
of 35mm


DIMENSIONS:
86 x 86mm

FIXING CENTRES:
60.3mm

BS.546: 1950

SOCKET OUTLETS 13 AMP

FLUSH

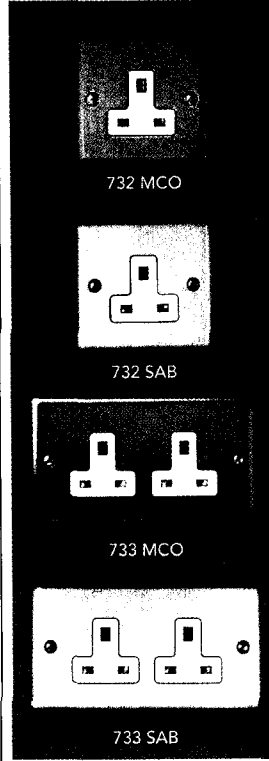

- 732 MCO** 10
- 732 SAB** 10
- 1 GANG
- 733 MCO** 5
- 733 SAB** 5
- 2 GANG

MOUNTING BOXES

FLUSH:
1 GANG: 866 ZIC
2 GANG: 886 ZIC

SURFACE:
1 GANG: 2001 ALM
2003 ALM
2 GANG: 2002 ALM
2004 ALM


Boxes have a minimum depth
of 35mm

DIMENSIONS:
1 gang: 86 x 86mm
2 gang: 86 x 146mm

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm

BS.1363: Pt 2: 1995

SURFACE

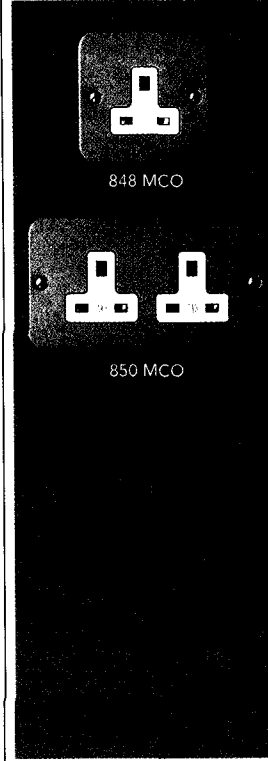

- 848 MCO** 5
- 1 GANG
- 850 MCO** 5
- 2 GANG

MOUNTING BOXES

Supplied with mounting boxes
without knockouts
Earth terminal fitted in boxes.

Spare Boxes with and without
knockouts are available. See
page 40.


DIMENSIONS:
1 gang: 81 x 81 x 43mm
2 gang: 77 x 136 x 43mm

BS.1363: Pt 2: 1995

CE For CE marking
information
see page 268

15 AMP 127V

FLUSH

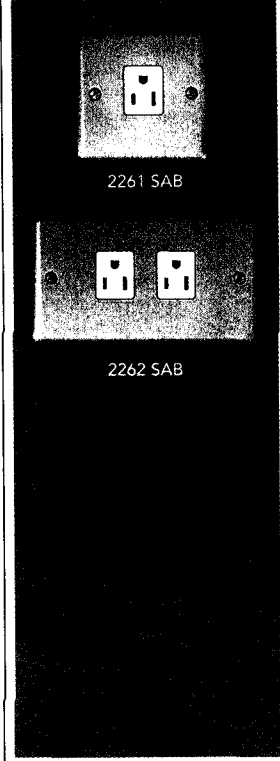

- 2261 MCO** 10
- 2261 SAB** 10
- 1 GANG
2 GANG: 886 ZIC
(NON UK)
- 2262 MCO** 5
- 2262 SAB** 5
- 2 GANG
(NON UK)

MOUNTING BOXES

FLUSH:
1 GANG: 866 ZIC
2 GANG: 886 ZIC

SURFACE:
1 GANG: 2001 ALM
2003 ALM
2 GANG: 2002 ALM
2004 ALM

Boxes have a minimum depth
of 35mm

These products are 2 pole with
earthing contact

DIMENSIONS:
1 gang: 86 x 86mm
2 gang: 86 x 146mm

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm

SSA 444: 1985