



order number : 738


## Receptacle

with high heat resistant contact carriers and nickel plated contacts

16A7P 6H400V panel mounted receptacle

IP44

with high heat resistant contact carriers and nickel plated contacts

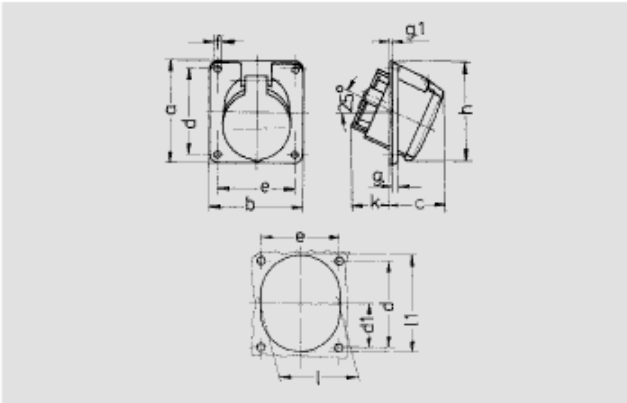

| Zeichnung               | Amp. | 16   | 32   |
|-------------------------|------|------|------|
| 1 MB 256                | Pole | 7    | 7    |
| Maße in mm              | a    | 100  | 100  |
|                         | b    | 92   | 92   |
|                         | c    | 48   | 51   |
|                         | d    | 85   | 85   |
|                         | d1   | 42,5 | 45,5 |
|                         | e    | 77   | 77   |
|                         | f    | 5,1  | 5,1  |
|                         | g    | 6    | 6    |
|                         | g.1  | 2    | 2    |
|                         | h    | 100  | 102  |
|                         | k    | 39   | 58   |
|                         | l    | 78   | 78   |
| Leiterquerschnitt       | l1   | 78   | 87   |
| von bis mm <sup>2</sup> |      | 1,5  | 2,5  |
|                         |      | —4   | —10  |

 Article-group : **1044**

voltages : 400V

rated current : 16A

pole : 7 pole

IP protection types : IP44

position of ground contact : 6h

packing unit : 0010

flange, fixing hole : FL 100x92mm BL 85x77mm N20°







pilot contact (63A-125A) : without pilot-contact

contact carriers : reliable contact frame

contact technique : screw contact

weight : 215 g

### PART NUMBERS

| V           | 110V  | 230V  | 400V  | 500V  | >50-500V  |   |
|-------------|---|---|---|---|---|---|
| Hz          | 50,60   | 50,60   | 50,60   | 50,60   | 100-300   | 300-500   |
| colour      |  |  |  |  |  |  |
| amp.        |   |   |   |   |   |   |
| <b>16 A</b> | 7   | 737   | <u>738</u>  | 1045  |   |   |
| <b>32 A</b> | 7   | 739   | 740   | 1050  |   |   |