


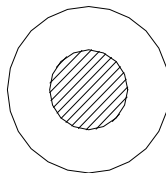

Product Name:	MIL-W-22759/9 24AWG
Product Discription:	MIL-W-22759/9 24AWG
Specification No.:	
Customer's Name:	

Description					Construction					
Rated Voltage:		1000V			Conductor		Stranded Sliver plated copper			
Rated Temperature:		200℃			Size(AWG)		24			
Reference Standard:		MIL-W-22759/9			Construction(±0.008mm)		19/0.127			
Cross Section					Stranded Dia.(mm)Ref.		0.63			
					Insulation Material		PTFE			
					Insulation Color		ANY COLOR			
					Ave Thickness(mm)		0.38			
					Insulation Dia.(±0.08mm)		1.37			
Marking					Remark:					
No marking on the cable jacket					8776168 Red 8776165 Blue					
					8776152 Black 8776162 White					
					8776156 Brown					
Applications					Characteristics				Customer Approve	
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.					Test Item			Standard Value		Seal & Stamp
					Test Material			PTFE(ROHS)		
					Insulation resistance(20℃ MΩ*m			1000		
					Vol. Tesr(AC.V.60S) (V)			2000		
					Flammability Test			VW-1		
Revisions					Max.DC Resistance(20℃ Ω/km)			77.4(MAX)		
Version	Description	Drawn by	Approved by	Date						
0	New document issue	Danniel	Jason	19/05/2015						
								Signature:		
								Date:		