


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
19,05	45,237	15,494	27,5	27,5	12000	18000	LM 11949/910/Q

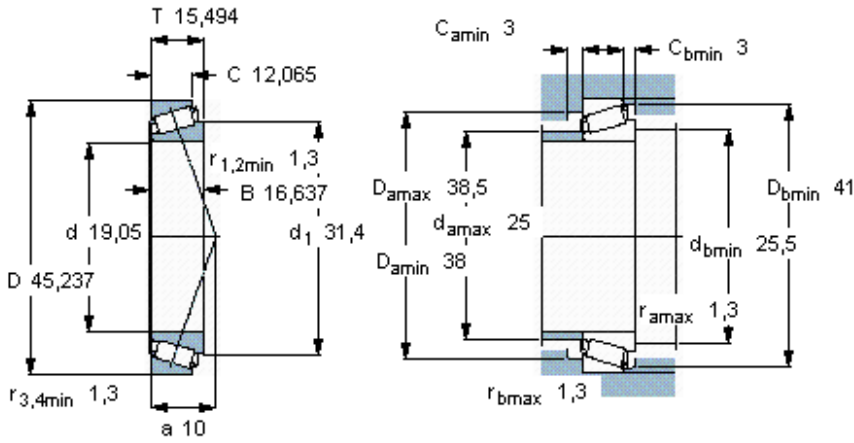

Calculation factors

$e = 0,3$

$Y = 2$

$Y_0 = 1,1$