


# Datasheet

## RS Pro 2 Core Multicore Speaker Cable, PVC Insulation 60V

Stock No: 714-0313



| Cable Construction                   |                                     |
|--------------------------------------|-------------------------------------|
| <b>Conductor</b>                     | <b>Tinned Copper</b>                |
| Construction                         | T0.2±0.008×13                       |
| Standard Dia.(mm)                    | 0.34                                |
| <b>Insulation</b>                    | <b>PVC</b>                          |
| Thickness                            | 0.57                                |
| Insulation Dia.(±0.1mm)              | 2.0×2                               |
| Insulation Color                     | Grey                                |
| Marking                              | One Black Stripe on one leg of Twin |
| <b>Print Marking</b>                 |                                     |
| 2 Core 7/0.25mm 60 V PVC [MM] [WkYr] |                                     |
| <b>Packaging</b>                     |                                     |
| 100M/Cardboard Reel                  |                                     |

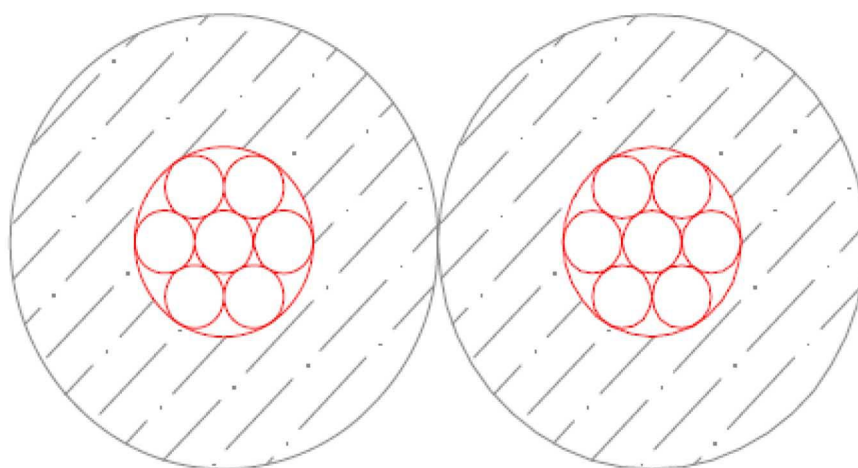

### Electrical Characteristics

|                                                        |       |
|--------------------------------------------------------|-------|
| Max.Conductor DC Resistance at 20 °C ( $\Omega$ /Km)   | <55.2 |
| Min.Insulation DC Resistance at 20 °C (M $\Omega$ *Km) | 200   |
| Rated Temperature(°C)                                  | 80    |
| Rated Voltage (V)                                      | 60    |