




ENGLISH

Datasheet

Stock No: 522-468

RS Pro 12 Core YY Control Cable Unscreened Polyvinyl Chloride PVC Sheath

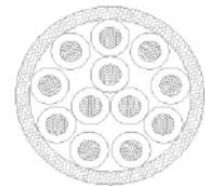

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Manufactured to VDE 2050

Electrical Characteristics:

Max. Conductor DC Resistance at 20°C (Ω/Km) :
<28.1

Min. Insulation DC Resistance at 20°C (MΩ*KM) :
>500

Current Rating : 6 A

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): 0.20±0.008 x 24

Insulation: PVC

Insulation Dia. (mm): 2.34±0.1 x 12C

Tape Mylar: ≥115%

Jacket: PVC

Outer Dia. (mm): 10.4±0.25

Colour:

The color of the insulation: Black x 11 cores
(with numbering) , Yellow/Green

The jacket color: Grey (RAL-7001)

Marking(3times/m):

RS 522468 YY/NR 12 Core x 0.75mm²