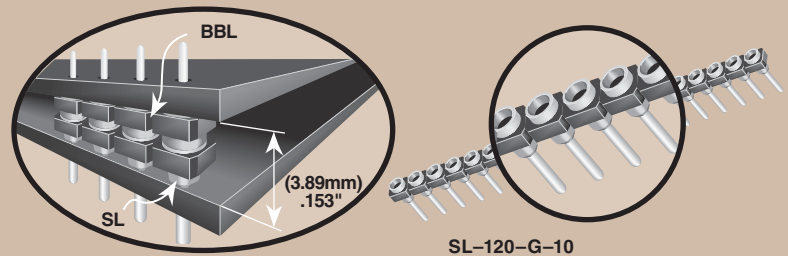


(2,54mm) .100"

SL, SDL SERIES



SL-120-G-10

LOW PROFILE MACHINED SOCKET STRIPS

FEATURES

- Achieve low profile without sacrificing insertion depth!
- Choice of four precision screw machined lead styles.
- Exceptionally low profile, down to (2,11mm) .083" off of board.
- Mates with BBL or BDL for board stacking spaces down to (3,89mm) .153"

SPECIFICATIONS

For complete specifications see www.samtec.com?SL or www.samtec.com?SDL

Insulator Material:

Black Glass Filled

Polyester



Contact/Shell Materials:

BeCu/Brass

Plating: Au or Sn over 50µ" (1,27µm) Ni

Operating Temp Range:

-55°C to +125°C with Gold

-55°C to +105°C with Tin

Current Rating:

1A

Contact Resistance:

10 mΩ max

Insertion Force:

(Single contact only)

Standard = 9 oz (2,50N) avg.,

16oz (4,45N) max

((0,43mm) .017" DIA probe)

Low Insertion Force =

2.5oz (0,70N) avg.,

5.5oz (1,53N) max

((0,43mm) .017" DIA probe)

Withdrawal Force:

(Single contact only)

Standard = 2.5oz (0,70N) avg.,

1.5oz (0,42N) min

((0,43mm) .017" DIA probe)

Low Insertion Force =

2.0oz (0,56N) avg.,

0.5oz min

((0,43mm) .017" DIA probe)

RoHS Compliant:

Yes

Lead-Free Solderable:

Wave only

Mates with:
TS, TD, HTS, BBS, BBD,
BBL, BDL, BHS

TYPE STRIP

1

NO. PINS PER ROW

PLATING OPTION

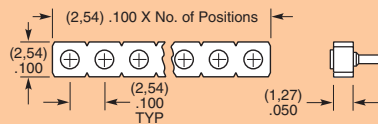
LEAD STYLE

SL

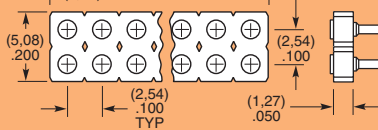
= Single Row Low Profile Socket Strip

SDL

= Double Row Low Profile Socket Strip



01 thru 32



01 thru 36

-G

= 30µ" (0,76µm)

Gold contact,

10µ" (0,25µm)

Gold shell

-T

= 30µ" (0,76µm)

Gold contact,

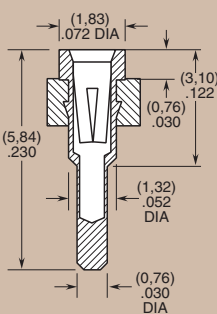
Tin shell

-TT

= Tin contact and shell (LIF not available)

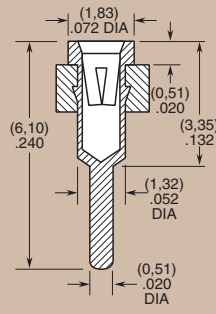
Low Insertion Force (LIF) Available

-10

Low Profile
(Hollow Leg)

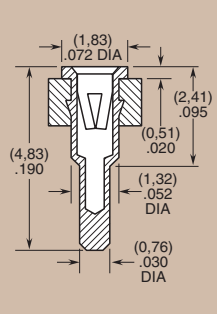
Contact Length = (2,11mm) .083"
Lead DIA Accepted = (0,38mm) .015" to (0,51mm) .020"
Insertion Depth = (2,67mm) .105" to (4,32mm) .170"
Style 10 Component Part No. = SC-3P1

-11

Low Profile
(Standard Mount)
For LIF specify -31

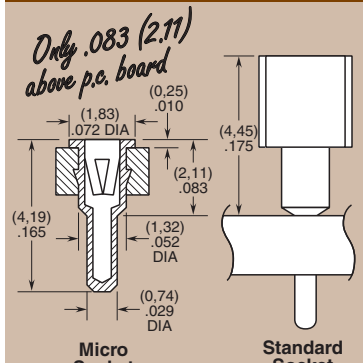
Contact Length = (1,58mm) .062"
Lead DIA Accepted = (0,41mm) .016" to (0,53mm) .021"
Insertion Depth = (2,03mm) .080" to (2,67mm) .105"
Style 11 Component Part No. = SC-4P1
Style 31 Component Part No. = EZ-4P1

-12

Micro-Socket
(Hollow Leg)

Contact Length = (1,58mm) .062"
Lead DIA Accepted = (0,41mm) .016" to (0,51mm) .020"
Insertion Depth = (1,65mm) .065" to (3,81mm) .150"
Style 12 Component Part No. = SC-5P1

-19

Micro-Socket
(Hollow Leg)
For LIF specify -39

Contact Length = (1,58mm) .062"
Lead DIA Accepted = (0,41mm) .016" to (0,51mm) .020"
Insertion Depth = (1,65mm) .065" to (3,56mm) .140"
Style 19 Component Part No. = SC-8P1
Style 39 Component Part No. = EZ-8P1

Standard Socket
(Reference only. Not available with SL & SDL)

Note: Some lengths, styles and options are non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683