

Price* : 281.38 GBP



Main

Range of product	Harmony XAP
Product or component type	Empty control station
Device short name	XB2SL
Product destination	For Ø 22 mm control and signalling units
Product front plate size	200 x 260 mm
Usable depth	115 mm
Number of cut-out	16 cut-outs
Material	Sheet steel
Product mounting	Flush mounting
IP degree of protection	IP547 conforming to NF C 20-010 IP54 conforming to IEC 60529

Complementary

Number of vertical rows	4
Product weight	3.9 kg

Environment


Protective treatment	TC
Ambient air temperature for storage	-40...70 °C
Ambient air temperature for operation	-25...70 °C
Electrical shock protection class	Class I conforming to IEC 60536 Class I conforming to NF C 20-030

Contractual warranty

Warranty period	18 months
-----------------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Dimensions

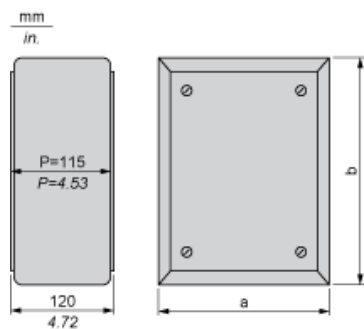


P Usable depth

a		b	
mm	in.	mm	in.
200	7.87	260	10.24

Refer to the product characteristics to get the number of cut-outs.

Cut-out interaxis dimensions (vertical mounting)

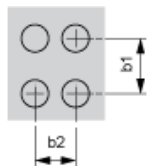

- b1 Vertical interaxis: 40 mm/1.57 in.
- b2 Horizontal interaxis: 30 mm/1.18 in.