


Price* : 153.09 GBP

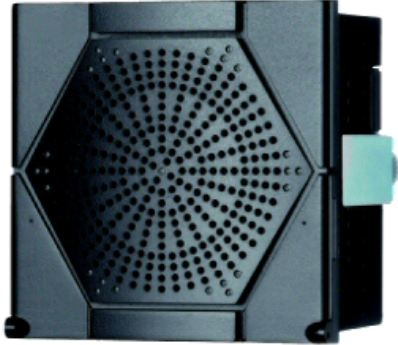

Main

Range of product	Harmony XVS
Product or component type	Electronic alarm
Device short name	XVS

Complementary

Colour	Black
Material	PC (polycarbonate) (terminal cover) PC (polycarbonate)/ABS (acrylonitrile butadiene-styrene) (body)
Product weight	0.4 kg
Marking	CE
Overvoltage category	Class II conforming to EN/IEC 61140
Mounting support	96 mm DIN rail
[Us] rated supply voltage	12...24 V DC
[Uimp] rated impulse withstand voltage	0.8 kV
Current consumption	250 mA at 12 V 292 mA at 12 V 292 mA at 24 V 354 mA at 24 V
Clamping connection capacity	<= 1 x 1.5 mm ²
Width	96 mm
Height	96 mm
Depth	58.1 mm

Environment

Discrete output type	PNP
Signalling type	16 tones alarm
Standards	EN/IEC 60947-1 EN/IEC 60947-5-1
Protective treatment	TC
Ambient air temperature for storage	-35...70 °C
Ambient air temperature for operation	-20...50 °C
IP degree of protection	IP54 (panel mounted) conforming to EN/IEC 60529

Noise level	0...96 dB (continuous or intermittent tone) at 1 m
-------------	--

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1346 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold

Contractual warranty

Warranty period	18 months
-----------------	-----------

Electronic Alarm

Dimensions

