

Mini-Lynx Fast-Start

ML FAST-START 827 B22 20W SLV

0035121

Range features



CE

PRODUCT OVERVIEW

Ordering number	0035121
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Stick
Lamp finish	Frosted
Dimmable	No
Cap/Base	B22
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351216
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	1200
Efficacy (Rated) (lm/w)	60
Watt (Nominal) (W)	20
Equivalent watt (W)	86
Voltage (V)	220-240

Mini-Lynx Fast-Start

ML FAST-START 827 B22 20W SLV

0035121

DATA TABLE

General data

Dry applications use only	Yes
Technology	Compact Fluorescent
Ordering number	0035121
Energy saving lamp	Yes
Average life (Rated) (h)	10000
Energy class	A
Average life (Nominal) (h)	10000
Lamp finish	Frosted
Lamp shape	Stick
Dimmable	No
Cap/Base	B22
Type	Mini-Lynx Fast Start T3 4U Stick
EAN code	5410288351216
E-number SE	8357547
Long description	
Product name	ML FAST-START 827 B22 20W SLV
Lamp mercury content (mg)	<2.5
Starting time (max) (s)	< 1.0 Sec
Warm-up time to 60% of full light (max) (s)	< 40 s
Control gear required	No
IEC Reference	IEC 60968
IEC Reference 2	IEC 60969
IEC Reference 3	IEC 55015
ILCOS code	FBTH-20/27/1b-B22-48/136
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	30000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25° C, cap-up, Stated lumen output may vary if operated in non-standard position

Mini-Lynx Fast-Start

ML FAST-START 827 B22 20W SLV

0035121

Optical data

Light colour	827 Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Lumen maintenance at end of nominal life (%)	= 75.0 %
Luminous flux (Rated) (lm)	1200
Luminous flux (Nominal) (lm)	1200
Chromaticity coordinate Y	0.420
Chromaticity coordinate X	0.463

Electrical data

kWh per 1000 hours burning time	20
Efficacy (Rated) (lm/w)	60
Watt (Nominal) (W)	20
Watt (Rated) (W)	20
Equivalent watt (W)	86
Voltage (V)	220-240
Current (A)	0.150
Lamp power factor	> 0.55

Physical data


Weight (kg)	0.08
Lamp Length (mm) - C/L	136
Max. Lamp Diameter (mm) - D	48
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	15.20 x 4.90 x 4.60
Outer package dimensions (L x W x H) (cm)	25.00 x 11.00 x 17.00

Mini-Lynx Fast-Start

ML FAST-START 827 B22 20W SLV

0035121

TECHNICAL DRAWINGS

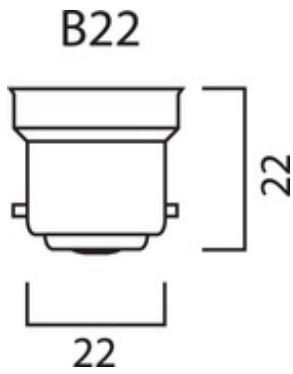

ENERGY LABEL

