

Euromas II

Enclosure, ABS




ET 212
Order no.: 63212000

Characteristics

Colour	light grey
Colour of enclosure group	Light grey, similar to RAL 7035; special colours on request
Protection class	IP 65
Enclosure material	ABS, PC (UV stabilised); seal made of CR; UL 94 V0 types on request; for details see Technical Information
Scope of delivery	Lid and base, self-tapping coarse-pitch thread lid screws made of V2A

Dimensions

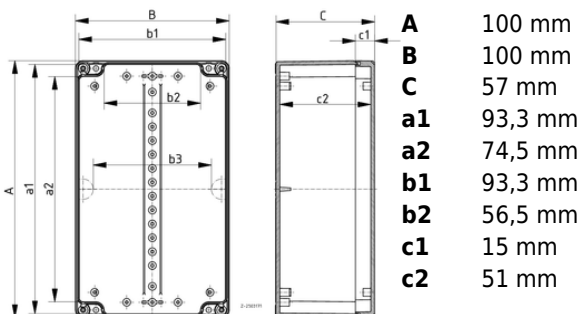

Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a [pressure compensation](#) element.

» [Additional information](#)

Technical documentation

Technical drawings

Product drawing in DXF format:
[63212000 ET 212.dxf](#) (788 KB)
3D product data in STEP format:
[63212000 ET 212.stp](#) (1.3 MB)
Drawing for mechanical processing:
[63212000 ET 212-G.dxf](#) (445 KB)
Product drawing in PDF format:
[63212000 ET 212.pdf](#) (81 KB)

Technical information

[ET-63-01 ENG.pdf](#) (54 KB)
[ET-63-01a.pdf](#) (55 KB)
[EM-62-02 EN 2012.pdf](#) (54 KB)
[EM-62-02 2012.pdf](#) (55 KB)

Material data

» [Important information regarding the following material data](#)

Important information regarding the following material data:

Please note that the information in the material database is based on current knowledge. The tests on basic materials and dyestuffs were carried out and certified by the manufacturers of the material. Changes to the certified values and characteristics may occur during manufacture of the moulding compound and as a result of the addition of any dyestuffs. Any specific or tacit guarantee or warranty or assurance of characteristics or any other liability in connection with the use of the information contained in these certificates is excluded. The customer is not released from the obligation to check whether the materials used correspond to his conditions of use in accordance with the currently valid legal requirements.

×

I have read and agreed to this information.

ABS MMIA Polyman

[Materialdatenblatt deutsch](#)

[Material datasheet english](#)

[UL-Karte/Card](#)

ABS Elix H605

[Materialdatenblatt deutsch](#)

[Material datasheet english](#)

[UL-Karte/Card](#)

ABS Cicolac GPM5500S

[Materialdatenblatt deutsch](#)

[Material datasheet english](#)

[UL-Karte/Card](#)

Downloads

Product brochure

[Euromas II GB.pdf](#) (362 KB)

Suitable for the enclosure



Rubber feet

22009000

[GF](#)

Polyurethane, 65-75 Shore Black



Wall brackets, screw-on at rear

22010000

[EM-WL](#)



Screw covers

22080000

[EM-SA](#)



Mounting panels, laminated paper

22212000

[M](#)

For EM/ET 212**



DIN rail acc. to DIN EN 60715 TH 15

22150901

[TS 15](#)

For EM/ET 212



DIN rail acc. to DIN EN 60715 G 32

22320901

[TS 32](#)

For EM/ET 212



DIN rail acc. to DIN EN 60715 TH 35

22350901

[TS 35](#)

For EM/ET 212



Screws (SHR) and distance bolts (DIBLZ) for mounting bosses in plastic enclosures

59006219

[SHR Z KA30x6](#)

SD = 3.0 / ND = 2.4-2.6 / KD = 5.6

* = Available on request