

# 73 06 160


## KNIPEX X-Cut Compact Diagonal Cutter



- Compact and 25 % less weight. Powerful and precise
- Cuts finest strands as well as multi-core cables and piano wires.
- box-joint design: highest stability with low weight
- doubly supported joint axis for heaviest duty
- high cutting performance with minimum effort due to optimum co-ordination of the cutting edge angle and transmission ratio
- large opening width for thicker cables
- cuts precisely, even through fine copper wires
- compact, low-weight construction
- universally usable, in the assembly, maintenance and production
- Chrome vanadium heavy-duty steel, forged, oil-hardened

40 % less effort required compared to diagonal cutters of the same length  
with double mounted hinged joint

<b>Article No.</b>	73 06 160
<b>EAN</b>	4003773075141
<b>Head</b>	
<b>Pliers</b>	chrome plated
<b>Handles</b>	insulated with multi-component grips, VDE-tested
<b>Insulation standard</b>	IEC 60900 DIN EN 60900
<b>medium hard wire Ø mm</b>	3,8
<b>hard wire Ø mm</b>	2,7
<b>piano wire Ø mm</b>	2,2
<b>Cutting capacity copper cable, multiple-stranded (diameter) Ø mm</b>	12,0
<b>soft wire Ø mm</b>	4,8
<b>Length mm</b>	160
<b>Length mm</b>	160
<b>Net weight g</b>	175

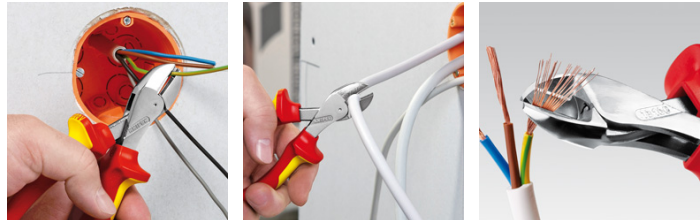

technical change and errors excepted

