



Emerg.stop/swit.off but.,non-ill.rot.rel

EATON






Powering Business Worldwide™



Part no.
Article no.
Catalog No.

M22-PVT
263467
M22-PVTQ

Delivery programme

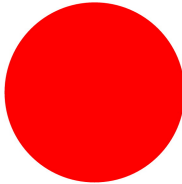
| | | | |
|----------------------------|---|----|---|
| Approval | | |     |
| Product range | | | RMQ-Titan (drilling dimensions 22.5 mm) |
| Basic function | | | Emergency stop pushbutton/ emergency-stop button |
| Description | | | Turn to release |
| Construction type | | | Mushroom-shaped |
| Diameter | ∅ | mm | 38 |
| Colour | | | |
| Mushroom head | | | Red |
| RAL Value | | | RAL 3000 |
| | | |  |
| Function | | | Turn-release |
| Illumination | | | Without illumination |
| Front ring | | | without front ring |
| Connection to SmartWire-DT | | | yes |
| Instructions | | | Release by turning |
| Notes | | | |
| Release by turning | | | |
| Button diameter 38 mm | | | |

Approvals

Product Standards
UL File No.
UL Category Control No.
CSA File No.
CSA Class No.
North America Certification
Degree of Protection

IEC/EN 60947-5; UL 508; CSA-C22.2 No. 14-05; CSA-C22.2 No. 94-91; CE marking
E29184
NKCR
012528
3211-03
UL listed, CSA certified
UL/CSA Type 3R, 4X, 12, 13

General

| | | | |
|----------------------|------------------|----------------------|---|
| Standards | | | IEC/EN 60947 VDE 0660 |
| Lifespan, mechanical | Operations | x 10 ⁶ | > 0.1 |
| Operating frequency | Operations/ h | |  600 |
| Actuating force | | n | 50 |
| Protection type | | | IP67, IP69K |
| Climatic proofing | | | Damp heat, constant, to IEC 60068-2-78 Damp heat, cyclic, to IEC 60068-2-30 |
| Ambient temperature | | °C | |
| Open | | °C | - 25 - + 70 |

| | | |
|-----------------------------|---|---|
| Mounting position | | As required |
| Mechanical shock resistance | g | 50 Shock duration 11 ms Sinusoidal according to IEC 60068-2-27 |


Technical data ETIM 5.0

Low-voltage industrial components (EG000017) / Front element for mushroom push-button (EC001038)

Electric engineering, automation, process control engineering / Low-voltage switch technology / Command and alarm device / Front element for mushroom push-button actuators (ecl@ss8-27-37-12-12 [AKF030010])

| | | |
|-----------------------------|----|---------------------------|
| Colour button | | Red |
| Construction type lens | | Round |
| Diameter cap | mm | 38 |
| Hole diameter | mm | 22 |
| Width opening | mm | 22 |
| Height meter opening | mm | 6 |
| Degree of protection (IP) | | IP67 |
| Type of button | | Flat |
| Suitable for illumination | | No |
| Switching function latching | | Yes |
| Spring-return | | No |
| With front ring | | No |
| Material front ring | | - |
| Colour front ring | | Chrome |
| Suitable for emergency stop | | Yes |
| Unlocking method | | Turn unlatching mechanism |

Dimensions

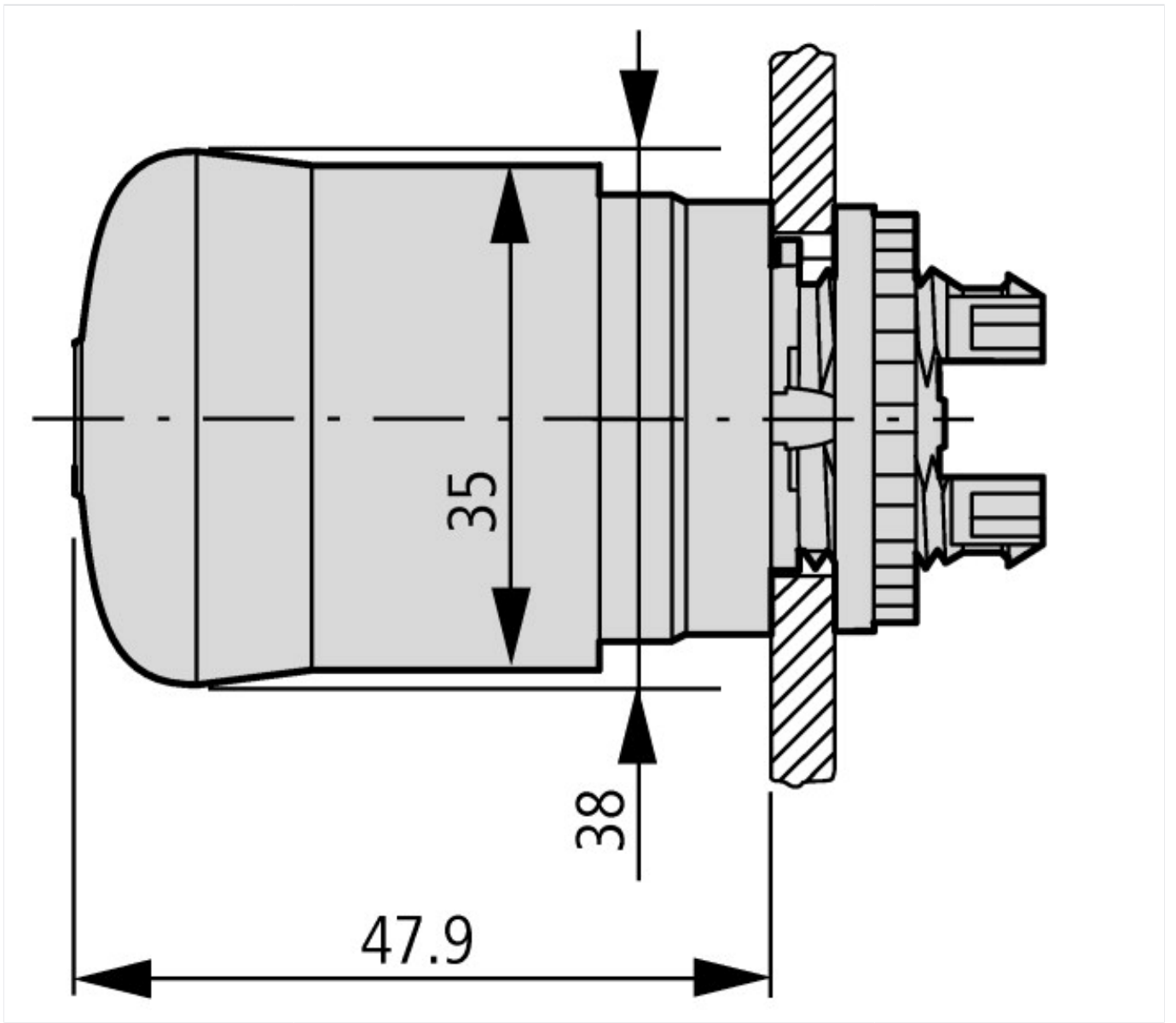

Additional product information (links)

IL04716005Z RMQ-Titan: Emergency stop buttons, Emergency stop buttons | IL04716002Z*.pdf;IL04716002Z

IL04716005Z RMQ-Titan: Emergency stop buttons, Emergency stop buttons | IL04716002Z*.pdf;IL04716002Z

ftp://ftp.moeller.net/DOCUMENTATION/AWA_INSTRUCTIONS/IL04716005Z2012_02.pdf