

## ECO PRO CL P 30 W 230 V E27

HALOGEN ECO PRO CLASSIC P | Halogen lamps, classic mini-ball shape



### Areas of application

- General illumination
- Mood lighting
- Entrance lighting
- Mirror lighting

### Product benefits

- Simple direct replacement for conventional incandescent lamps
- The same pleasant quality of light as that of an incandescent lamp
- Instant 100 % light, no warm-up time
- Contains no mercury
- UV filter

### Product features

- Average life: 2,000 h
- 100 % dimmable
- Perfect color rendering ( $R_a : 100$ )



**HALOGEN  
ECO**

Technical data

Electrical data

|                                        |              |
|----------------------------------------|--------------|
| Nominal wattage                        | 30.00 W      |
| Nominal voltage                        | 230 V        |
| Rated wattage                          | 30.00 W      |
| Claimed equiv. conventional lamp power | 40 W         |
| Power factor $\lambda$                 | 1.00         |
| Energy consumption                     | 30 kWh/1000h |


Photometrical data

|                                         |            |
|-----------------------------------------|------------|
| Nominal luminous flux                   | 405 lm     |
| Color temperature                       | 2700 K     |
| Light color as per EN 12464-1           | Warm White |
| Rated luminous flux                     | 405 lm     |
| Color rendering index Ra                | 100        |
| Lumen main.fact.at end of nom.life time | 0.80       |

Light technical data

|                     |        |
|---------------------|--------|
| Starting time       | 0.0 s  |
| Warm-up time (60 %) | 0.00 s |

Dimensions & weight

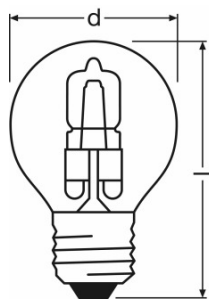

Product line drawing

|                |         |
|----------------|---------|
| Diameter       | 45.0 mm |
| Overall length | 74.0 mm |
| Length         | 74.0 mm |

Product datasheet

|                           |         |
|---------------------------|---------|
| Light center length (LCL) | 60.0 mm |
| Outer bulb                | P45     |

Colors & materials


|                      |        |
|----------------------|--------|
| Lamp mercury content | 0.0 mg |
| Mercury-free         | Yes    |

Lifespan

|                            |                     |
|----------------------------|---------------------|
| Nominal lamp life time     | 2000 h              |
| Rated lamp life time       | 2000 h              |
| Number of switching cycles | 50000 <sup>1)</sup> |

<sup>1)</sup> At 1 min on / 3 min off

Additional product data

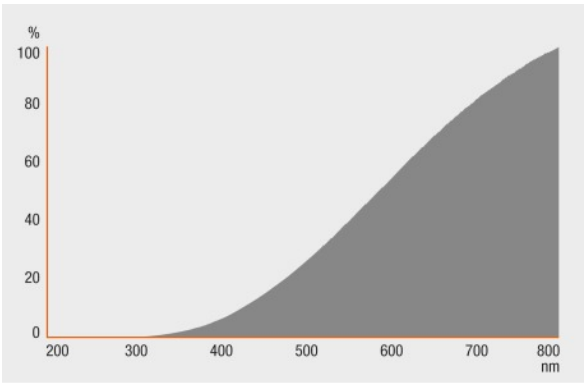

Spectral power distribution

|                             |     |
|-----------------------------|-----|
| Base (standard designation) | E27 |
|-----------------------------|-----|

Capabilities

|                  |     |
|------------------|-----|
| Burning position | Any |
| Dimmable         | Yes |

Certificates & standards

Product datasheet

|                         |   |
|-------------------------|---|
| Energy efficiency class | D |
|-------------------------|---|

Country specific categorizations

|                 |                          |
|-----------------|--------------------------|
| ILCOS           | HSGSP/C/UB-30-230-E27-60 |
| Order reference | 64542 P PRO 30W          |

Country specific information

| Product code  | METEL-Code | SEG number | STK number | UK Org |
|---------------|------------|------------|------------|--------|
| 4008321998286 | -          | 8327118    | 4730102    | -      |

## Product datasheet

---

### Logistical Data

---

| Product code  | Product description            | Packaging unit<br>(Pieces/Unit) | Dimensions (height x<br>width x length) | Volume               | Gross weight |
|---------------|--------------------------------|---------------------------------|-----------------------------------------|----------------------|--------------|
| 4008321998286 | ECO PRO CL P 30 W<br>230 V E27 | Folding carton box<br>1         | 46 mm x 46 mm x<br>77 mm                | 0.16 dm <sup>3</sup> | 24.00 g      |
| 4008321998293 | ECO PRO CL P 30 W<br>230 V E27 | Shipping carton box<br>20       | 193 mm x 85 mm x<br>235 mm              | 3.86 dm <sup>3</sup> | 590.00 g     |

---

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

---

### Disclaimer

---

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.