

Switches

Type	Colour	IP-IK	Qty per package	Ref. No.
------	--------	-------	-----------------	----------

Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE.
External dimensions : 72 x 72 x 47 mm. .

Standard

Assembly surface mounted rockers become illuminated using bulbs and indicators in option. They can carry a label using the legended push in option (see accessories page 12).

Rocker

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35021
	White	IP 55 - IK 07	10	ENN39021

Double pole switch

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35033
	White	IP 55 - IK 07	10	ENN39033

Changeover

Assembly surface mounted	Grey	IP 55 - IK 07	5	ENN35023
	White	IP 55 - IK 07	5	ENN39023

Illuminated

Illuminated rockers are provided with a mounted bulb.

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35024
	White	IP 55 - IK 07	10	ENN39024

Doubles

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35022
	White	IP 55 - IK 07	10	ENN39022

P124543



P124547



Push-buttons

Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE.

Standard

Push-buttons 10A

The push-buttons assembly surface mounted become illuminated using bulbs and indicators in option. They can carry a label using the legended push in option (see accessories page 12).

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35026
	White	IP 55 - IK 07	10	ENN39026

Push-buttons 10A legended

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35029
	White	IP 55 - IK 07	10	ENN39029

Push-buttons 10A with picto

Light picto assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35032
	White	IP 55 - IK 07	10	ENN39003
Bell picto assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35030
	White	IP 55 - IK 07	10	ENN39002

Illuminated

Illuminated rockers are provided with a mounted bulb.

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35028
	White	IP 55 - IK 07	10	ENN39028

Illuminated 10A push-buttons with picto

Light picto assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35001
	White	IP 55 - IK 07	10	ENN39001
Bell picto assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35000
	White	IP 55 - IK 07	10	ENN39000

Double push-buttons

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35326
--------------------------	------	---------------	----	----------

Illuminated

Double illuminated push-button. Provided without bulb (see page 12).

Assembly surface mounted	Grey	IP 55 - IK 07	10	ENN35228
	White	IP 55 - IK 07	10	ENN39228

P124543



P124548



P124547



P124546



Specific switches

	Type	Colour	IP-IK	Qty per package	Ref. No.
P124545	Roller shutter				
	External dimensions : 72 x 72 x 47 mm.				
P124550	Rocker 10A - 250 V				
	Doubles switches interlocked for a direct control. Maximum controlled power : 500 VA				
P124541	Assembly surface mounted	Grey	IP 55 - IK 07	1	ENN35041
		White	IP 55 - IK 07	1	ENN39041
P124544	Double push-button				
	Double push-button for an automatic control. Stop by pushing simultaneously the 2 pushes.				
P124544	Assembly surface mounted	Grey	IP 55 - IK 07	1	ENN35042
		White	IP 55 - IK 07	1	ENN39042
P124544	Illuminated time delay switches				
	Power supply: 230 V - 50/60 Hz. Conforming to EN 60669-2-3. External dimensions: 72 x 72 x 70 mm Timer adjustable each 2 min. from 2 to 14 min.				
P124544	<ul style="list-style-type: none"> ■ Turn the switch until it stops to set the delay on 14 min. ■ For a shorter duration, turn it to an intermediate position. 				
	<p>At any time, it is possible to stop the timer by switching it to its starting position. Accepted voltage: 10 A (resistive, $\cos \varphi = 1$) 6 A (inductive, $\cos \varphi = 0.6$) Cabling with 2 wires (no neutral). Provided with mounted bulb.</p>				
P124544	Assembly surface mounted	Grey	IP 55 - IK 07	1	ENN35067
		White	IP 55 - IK 07	1	ENN39067
P124544	Electronic timer				
	Power supply: 230 V - 50/60 Hz Conforming to EN 60 669-2-1. Timer adjustable continuously from 1 to 15 min.				
P124544	To activate the timer, press the push-button. Any further pressure on the push restarts the timer.				
	<p>For remote control, one or more push-buttons may be associated with the timer. Charges accepted:</p> <ul style="list-style-type: none"> ■ LV halogen lamps: 300 VA; 230 V: 600 W incandescent and halogen lamps; fluorescent lamps \varnothing 26/38: 300 VA. ■ Fan motor: 160 VA ■ Radiator: 1000 W 				
P124544	Note: do not control power transformers.				
	Cabling with 2 wires (no neutral). Provided with mounted bulb.				
P124544	Assembly surface mounted	Grey	IP 55 - IK 07	1	ENN35066
		White	IP 55 - IK 07	1	ENN39066
P124592	Emergency stop 10A - 250 V				
	Assembly surface mounted emergency stop. External dimensions 72 x 72 x 85 mm. Provided with marking «Emergency stop». 230 V - 50/60 Hz. Contact O unipolar.				
P124592	Push-pull	Yellow and red	IP 55 - IK 07	1	ENN35051
	455 key	Yellow and red	IP 55 - IK 07	1	ENN35052
P124592	Quarter-turn	Yellow and red	IP 55 - IK 07	1	ENN35053
	Key switch				
P124590	230 V - 50/60 Hz. External dimensions : 72 x 72 x 774 mm. Key removal in central position.				
	3 positions Assembly surface mounted	Black and grey	IP 55 - IK 07	1	ENN35061

Power sockets with earth pin

P124570



Type	Colour	IP-IK	Qty per package	Ref. No.
------	--------	-------	-----------------	----------

Sockets conforming to NF-USE standard:

- Conforming to NF C 61314. Admitted to the NF-USE quality mark under the no 830 by the LCIE.

- Conforming to NF C 15100, with a shutter to protect children.

Easy cabling using box terminals.

The cover opens 180°.

External dimensions : 72x72x57 mm

Standard

Packaged by 10 units

PC 2P+T NF-USE assembly surface mounted	Grey	IP 55 - IK 07	10	ENN36030
	White	IP 55 - IK 07	10	ENN39030

Can be unpacked

PC 2P+T NF-USE assembly surface mounted	Grey	IP 55 - IK 07	10	ENN36730
---	------	---------------	----	----------

Power socket 2P+E with visual coding

Intended to visually differentiate sockets connected to the standard grid (white) and those backed up by an UPS.

PS 2P+E visual coding NF-USE assembly surface mounted	Grey	IP55 - IK 07	10	ENN36035
---	------	--------------	----	----------

Pack of 10 power sockets + 5 rockers

Pack of 10 PS NF-USE + 5 rockers assembly surface mounted	Grey	IP 55 - IK 07	1	ENN36036
---	------	---------------	---	----------

P124586



Network sockets

P124588



RJ45 sockets

External dimensions : 72 x 72 x 57 mm.

Cat. 5, UTP assembly surface mounted	Grey	IP 55 - IK 07	1	ENN36050
Cat. 5, FTP shielded assembly surface mounted	Grey	IP 55 - IK 07	1	ENN36051
Cat. 6, FTP assembly surface mounted	Grey	IP 55 - IK 07	1	ENN36055

Fault centralisation



P124565

Type	Colour	IP-IK	Qty per package	Ref. No.
------	--------	-------	-----------------	----------

Sensors

External dimensions : 72x72x70 mm.
Voltage : 12 V DC. Output: 1 A - 24 V.
Temperature and water sensors provided with probe.

Temperature sensor

Reports with an alarm any temperature increasing of the probe to a value higher than -15 °C (freezing temperature for example). The alarm state is indicated by a red indicator and a audible alarm (85 dB at 1 m) which stops by pressing a button. Power consumption at alarm: 25 mA.

Assembly surface mounted	Grey	IP 42 - IK 07	1	ENN35074
--------------------------	------	---------------	---	----------

Water sensor

Reports with an alarm the presence of water at the probe. The alarm state is indicated by a red indicator and a audible alarm (85 dB at 1 m) which stops by pressing a button. Power consumption at alarm: 30 mA.

Assembly surface mounted	Grey	IP 42 - IK 07	1	ENN35073
--------------------------	------	---------------	---	----------

Gas sensor

Reports with an alarm the presence of light gas (natural gas, town gas, methane) or heavy (butane, propane). Detection rate: 8% ± 2.5% of the lower limit of explosion (EN 50194).

These sensors indicate three status, according to the color of LEDs:

- Green: operational
- Red: alarm (with audible alarm 85 dB at 1 m).
- Orange: fault

Power consumption at alarm: 100 mA.

Light gas sensor	Grey	IP 42 - IK 07	1	ENN35076
------------------	------	---------------	---	----------

Assembly surface mounted				
--------------------------	--	--	--	--

Heavy gas sensor	Grey	IP 42 - IK 07	1	ENN35077
------------------	------	---------------	---	----------

Assembly surface mounted				
--------------------------	--	--	--	--

Sensors power supply

Transformer 230 V to 12 V

Transformers intended to provide power to Mureva sensors in 12 V DC SELV. Maximum power provided at alarm: 2200 mW. When several sensors are connected to the same transformer, total their respective powers (see table below). If the limit is exceeded, install a second power supply. Maximum limit between the transformer and the sensor: 100 m (depending on the section). Voltage: 230 V - 50/60 Hz. External dimensions : 72 x 72 x 70 mm.

Transformer	Grey	IP 42 - IK 07	1	ENN35079
-------------	------	---------------	---	----------

Assembly surface mounted				
--------------------------	--	--	--	--

Sensors	Power consumption
temperature	300 mW
water	360 mW
gas	1200 mW
alarm repeater	300 mW

Centralisation of sensors

Alarm repeater

The alarm repeater enables grouping, signalling and, if required, transmission of the alarm from one or several sensors connected on the monitoring loop. It can also transmit alarm detection to equipment responsible for its processing.

The alarm is signalled by a red indicator light and an audible warning (85 dB at 1 m) which can be stopped by push-button.

Voltage: 12 V DC. Power consumption at alarm: 25 mA. Output: 6A - 230 V.

External dimensions : 72 x 72 x 70 mm.

Alarm repeater	Grey	IP 42 - IK 07	1	ENN35078
----------------	------	---------------	---	----------

Assembly surface mounted				
--------------------------	--	--	--	--



P124564

Switches

P124679



Type	Colour	IP-IK	Qty per package	Ref. No.
------	--------	-------	-----------------	----------

Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE.
External dimensions : 72 x 72 x 47 mm. .

Standard

Assembly surface mounted rockers become illuminated using bulbs and indicators in option. They can carry a label using the legended push in option (see accessories page 12).

Rocker

Assembly surface mounted	Blue	IP 55 - IK 08	10	ENN35121
--------------------------	------	---------------	----	----------

Double pole switch

Assembly surface mounted	Blue	IP 55 - IK 08	10	ENN35133
--------------------------	------	---------------	----	----------

Push-buttons

Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE.

Standard

Assembly surface mounted push-buttons become illuminated using bulbs and indicators in option. They can carry a label using the legended push in option (see accessories page 12).

Push-button 10A assembly surface mounted	Blue	IP 55 - IK 08	10	ENN35126
---	------	---------------	----	----------

Illuminated

Illuminated push-buttons are provided with mounted bulbs.

Illuminated 10A P-B assembly surface mounted	Blue	IP 55 - IK 08	10	ENN35128
---	------	---------------	----	----------

Power sockets with earth pin

P124581



Sockets conforming to NF-USE standard:

- Conforming to NF C 61314. Admitted to the NF-USE quality mark under the no 830 by the LCIE.
- Conforming to NF C 15100, with a shutter to protect children.

Easy cabling using box terminals.

The cover opens 180°.

Standard

Power sockets 2P+T NF-USE

PC 2P+T NF-USE Impact surface mounted	Blue	IP 55 - IK 08	10	ENN36130
--	------	---------------	----	----------

Signaling accessories



P124584



P124592



P124583



P124591

Type	Colour	IP-IK	Qty per package	Ref. No.
------	--------	-------	-----------------	----------

Signaling bulbs

Signaling bulbs equipped with plugs to instal E14 type bulbs. Maximum power: 5 W à 230/250 V.
Made entirely of insulating material.
External dimensions : 72x72x57 mm. Provided without bulb.

Packaged by 10 units

Clear glass assembly surface mounted	Grey	IP 55 - IK 07	10	ENN34523
Red glass assembly surface mounted	Grey	IP 55 - IK 07	10	ENN34526
Green glass assembly surface mounted	Grey	IP 55 - IK 07	10	ENN34527

Can be unpacked

Clear glass assembly surface mounted	Grey	IP 55 - IK 07	10	ENN34723
Red glass assembly surface mounted	Grey	IP 55 - IK 07	10	ENN34726
Green glass assembly surface mounted	Grey	IP 55 - IK 07	10	ENN34727

Bulb accessory

Bulb E14, 5W - 250V	Grey	-	10	ENN34555
---------------------	------	---	----	----------

Bulkheads

Maximum power: 75 watts - 110-250 V.
Equipped with 3 waterproof entries.
Polycarbonate glass. Base in steel, polyester-based enclosure.
Provided without bulb.

Equipped with an E27 socket

E27 clear glass assembly surface mounted	Grey	IP 55 - IK 08	2	ENN34231
E27 orange glass assembly surface mounted	Grey	IP 55 - IK 08	2	ENN34251
E27 red glass assembly surface mounted	Grey	IP 55 - IK 08	2	ENN34261
E27 green glass assembly surface mounted	Grey	IP 55 - IK 08	2	ENN34271

Equipped with a B22 socket

B22 clear glass assembly surface mounted	Grey	IP 55 - IK 08	2	ENN34232
B22 orange glass assembly surface mounted	Grey	IP 55 - IK 08	2	ENN34252
B22 red glass assembly surface mounted	Grey	IP 55 - IK 08	2	ENN34262
B22 green glass assembly surface mounted	Grey	IP 55 - IK 08	2	ENN34272

Switches

P124574



Type	Colour	IP-IK	Qty per package	Ref. No.
------	--------	-------	-----------------	----------

Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE.
External dimensions : 72 x 72 x 47 mm .

Standard

Packaged by 10 units

Rocker componible surface mounted	Grey	IP 55 - IK 07	10	ENN37021
	White	IP 55 - IK 07	10	ENN39721

Can be unpacked

Rocker componible surface mounted	Grey	IP 55 - IK 07	10	ENN37720
	White	IP 55 - IK 07	10	ENN37921

Double

Packaged by 10 units

Double Rocker componible surface mounted	Grey	IP 55 - IK 07	10	ENN37022
	White	IP 55 - IK 07	10	ENN39722

Can be unpacked

Double Rocker componible surface mounted	Grey	IP 55 - IK 07	10	ENN37722
	White	IP 55 - IK 07	10	ENN37922

Push-buttons

P124577



Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE.
External dimensions : 72 x 72 x 47 mm

Standard

Push-button componible surface mounted	Grey	IP 55 - IK 07	10	ENN37026
	White	IP 55 - IK 07	10	ENN39726

Illuminated

Illuminated push-buttons are provided with a mounted bulb.

Packaged by 10 units

Illuminated P-B componible surface mounted	Grey	IP 55 - IK 07	10	ENN37028
	White	IP 55 - IK 07	10	ENN39728
Illum. P-B light picto componible surface mounted	Grey	IP 55 - IK 07	10	ENN37033
	White	IP 55 - IK 07	10	ENN39733
Illum. P-B bell picto componible surface mounted	Grey	IP 55 - IK 07	10	ENN37031
	White	IP 55 - IK 07	10	ENN39731

Can be unpacked

Illum. P-B light picto componible surface mounted	Grey	IP 55 - IK 07	10	ENN37764
	White	IP 55 - IK 07	10	ENN37964
Illum. P-B bell picto componible surface mounted	Grey	IP 55 - IK 07	10	ENN37762
	White	IP 55 - IK 07	10	ENN37962

Power sockets with earth pin

Sockets conforming to NF-USE standard:

- Conforming to NF C 61314. Admitted to the NF-USE quality mark under the no 830 by the LCIE.
- Conforming to NF C 15100, with a shutter to protect children.

Easy cabling using box terminals.

The cover opens 180°.

External dimensions : 72 x 72 x 57 mm

Standard

Power sockets 2P+T NF-USE

PC 2P+T NF-USE componible surface mounted	Grey	IP 55 - IK 07	10	ENN38030
	White	IP 55 - IK 07	10	ENN39830
PC 2P+T NF-USE front plate	Grey	IP 55 - IK 07	10	ENN38930

P124568



Accessories for componible surface mounted wiring devices

P124596 - P124598 - P124602 - P124604



Type	Colour	IP-IK	Qty per package	Ref. No.
------	--------	-------	-----------------	----------

Empty boxes

Empty boxes surface monted 16A

Empty boxes allowing to install front plate wiring devices.
Glow wire test: 650 °C - 30 s.

Cable entries :

- Simple or double empty boxes : 1 entry with E.V.A. membrane for cables and conduits + 1 flat tip
- Triple empty boxes : 2 entries with 1 E.V.A. membrane for cables and conduits + 2 flat tips

Empty box componible surface mounted	Grey	IP 55 - IK 07	10	ENN37911
	White	IP 55 - IK 07	10	ENN39911
Double empty box vertic. componible surface mounted	Grey	IP 55 - IK 07	5	ENN37912
	White	IP 55 - IK 07	5	ENN39912
Double empty box horiz. componible surface mounted	Grey	IP 55 - IK 07	5	ENN37914
	White	IP 55 - IK 07	5	ENN39914
Triple empty box horiz. componible surface mounted	Grey	IP 55 - IK 07	5	ENN37913
	White	IP 55 - IK 07	5	ENN39913

Frame for switches 47 x 47

Frame 47x47 low spring	Grey	IP 55 - IK 07	5	ENN35302
Frame 47x47	Grey	IP 55 - IK 07	5	ENN37301

Frame 45 x 45

Inteded to install 45x45 mm mecanisms in waterproof frames.

Packaged by 10 units

Frame 45x45 clear componible surface mounted	Grey	IP 55 - IK 07	10	ENN35004
Frame 45x45 smoked glass componible surface mounted	Grey	IP 55 - IK 07	10	ENN35005
Frame 45x45 opaque componible surface mounted	Grey	IP 55 - IK 07	10	ENN35006

Can be unpacked

Empty boxes 45x45 mm componible surface mounted	Grey	IP 55 - IK 07	5	ENN35303
Empty boxes 45x45 mm componible surface mounted	Grey	IP 55 - IK 07	5	ENN37303

Cable outlet cover

Cable outlet cover componible surface mounted

Couvercle sortie câble componible surface mounted	Grey	IP 55 - IK 07	10	ENN37731
	White	IP 55 - IK 07	10	ENN38991

E.V.A. cable entries (Easy Valve Access)

Standard Ø 20 mm entries for conduits (Ø 16 - 20 mm) or RO2V cables.
Flat tips (2 x Ø 13 mm + 1 x Ø 16 mm).

Standard Ø 20 E.V.A. entry	Grey	-	20	ENN35008
	White	-	20	ENN39008
Flat tip	Grey	-	20	ENN35007
	White	-	20	ENN39007

P124532



P124552



Switches

Type	Colour	IP-IK	Qty per package	Ref. No.
<p>Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE. External dimensions : 82 x 82 x 18,5 mm. Fixing clamps available in accessories, see page 12.</p>				
Standard without fixing clamps				
Packaged by 10 units				
Rocker assembly flush mounted	White	IP 44 - IK 08	10	ENN39121
Changeover complet encastré	White	IP 44 - IK 08	10	ENN39323
Can be unpacked				
Rocker assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34021
	White			ENN39133
Changeover assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34023
Illuminated without fixing clamps				
Illuminated rockers are provided with a mounted bulb.				
Illuminated rocker assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34221
	White	IP 44 - IK 08	10	ENN39221
Doubles without fixing clamps				
Packaged by 10 units				
Double rocker assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34012
	White	IP 44 - IK 08	10	ENN39112
Can be unpacked				
Switch + rocker assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34022
Switch + rocker without fixing clamps				
Switch + rocker assembly flush mounted	White	IP 44 - IK 08	10	ENN39122

Push-buttons

<p>Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE. External dimensions : 82 x 82 x 18,5 mm. Fixing clamps available in accessories, see page 12.</p>				
Standard without fixing clamps				
Packaged by 10 units				
P-B assembly flush mounted	White	IP 44 - IK 08	10	ENN39126
P-B legended assembly flush mounted	White	IP 44 - IK 08	10	ENN39129
Can be unpacked				
P-B assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34026
P-B legended assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34029
Push-buttons avec picto sans griffes de fixation				
P-B light picto assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34003
	White	IP 44 - IK 08	10	ENN39105
P-B bell picto assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34002
	White	IP 44 - IK 08	10	ENN39104
Illuminated without fixing clamps				
Illuminated push-buttons are provided with mounted bulbs.				
Packaged by 10 units				
Illum. 10A P-B light picto assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34001
	White	IP 44 - IK 08	10	ENN39103
Illum. 10A P-B bell picto assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34000
	White	IP 44 - IK 08	10	ENN39102
Can be unpacked				
Illuminated 10A P-B assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34028
	White	IP 44 - IK 08	10	ENN39128

Specific switches

Type	Colour	IP-IK	Qty per package	Ref. No.
Roller shutter without fixing clamps				

The product is set for an automatic control. Remove the springs during assembly to change it to an interlocked double switch for a direct control.

Can be unpacked: products individually labelled.

Fixing clamps available in accessories, see page 12.

Roller shutter assembly flush mounted	Grey	IP 55 - IK 07	1	ENN34041
	White	IP 55 - IK 07	1	ENN39141

Illuminated time delay switch without fixing clamps

Power supply: 230 V - 50/60 Hz. Conforming to EN 60669-2-3. External dimensions : 82 x 82 x 22,5 mm.

Timer adjustable each 2 min. from 2 to 14 min.

- Turn the switch until it stops to set the delay on 14 min.
- For a shorter duration, turn it to an intermediate position.

At any time, it is possible to stop the timer by switching it to its starting position.

Accepted voltage: 10 A (resistive, $\cos \varphi = 1$) 6 A (inductive, $\cos \varphi = 0.6$)

Cabling with 2 wires (no neutral). Provided with mounted bulb

References ENN34067 and ENN39167 can not be equipped with fixing clamps

Temporisateur lum. assembly flush mounted	Grey	IP 44 - IK 08	1	ENN34067
	White	IP 44 - IK 08	1	ENN39167



P124653

Power sockets with earth pin

Sockets conforming to NF-USE standard:

- Conforming to NF C 61314. Admitted to the NF-USE quality mark under the no 830 by the LCIE.
- Conforming to NF C 15100, with a shutter to protect children.

Easy cabling using box terminals.

The cover opens 180°.

External dimensions : 82 x 82 x 22,5 mm

Fixing clamps available in accessories, see page 12.

Standard without fixing clamps

Power sockets 2P+T NF-USE

PS 2P+E NF-USE assembly flush mounted	Grey	IP 44 - IK 08	10	ENN34030
	White	IP 44 - IK 08	10	ENN39130



P124632

Switches

P124622



Type	Colour	IP-IK	Qty per package	Ref. No.
------	--------	-------	-----------------	----------

Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE.
External dimensions : 45 x 45 mm.
Fixing clamps available in accessories, see page 12.

Standard without fixing clamps

Rocker compo. flush mounted	Grey	IP 44 - IK 08	10	ENN34121
	White	IP 44 - IK 08	10	ENN39421

Doubles without fixing clamps

Double Rocker compo. flush mounted	Grey	IP 44 - IK 08	10	ENN34122
	White	IP 44 - IK 08	10	ENN39422

P124629



Push-buttons

P124624



Conforming to EN 60669-1. Admitted to the NF-USE quality mark under the no 830 by the LCIE-UTE.
External dimensions : 45 x 45 mm.
Fixing clamps available in accessories, see page 12.

Standard without fixing clamps

Push-button compo. flush mounted	Grey	IP 44 - IK 08	10	ENN34126
	White	IP 44 - IK 08	10	ENN39426

Illuminated without fixing clamps

Illuminated push-buttons are provided with mounted bulbs.

Illuminated P-B compo. flush mounted	Grey	IP 44 - IK 08	10	ENN34128
	White	IP 44 - IK 08	10	ENN39428

P124627



Power sockets with earth pin

P124635



Sockets conforming to NF-USE standard:

- Conforming to NF C 61314. Admitted to the NF-USE quality mark under the no 830 by the LCIE.
- Conforming to NF C 15100, with a shutter to protect children.

Easy cabling using box terminals.

The cover opens 180°.

External dimensions : 45 x 45 mm


Fixing clamps available in accessories, see page 12.

Standard without fixing clamps

PC 16A 2P+T NF-USE compo. flush mounted	Grey	IP 44 - IK 08	10	ENN34130
	White	IP 44 - IK 08	10	ENN39430

Accessories for componible flush mounted wiring devices

P124653 - 124655

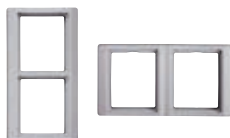

Double frames

Center-to-center distance 71 mm.

Double horiz. frame compo. flush mounted	Grey	IP 44 - IK 08	5	ENN34101
	White	IP 44 - IK 08	5	ENN39101
Double vert. frame compo. flush mounted	Grey	IP 44 - IK 08	5	ENN34151
	White	IP 44 - IK 08	5	ENN39151

Complementary and replacement accessories



Type	Colour	IP-IK	Qty per package	Ref. No.
Illuminated pushes + bulbs				
Changes a rocker or a push-button to an illuminated switch.				
Packaged by 10 units				
For surface mounted switches	Grey	-	10	ENN35200
	White	-	10	ENN39200
For flush mounted switches	Grey	-	10	ENN34100
	White	-	10	ENN39100
For impact switches	Blue	-	10	ENN35100
Can be unpacked				
For surface mounted switches	Grey	-	10	ENN35800
Legended pushes (without bulb)				
Compatible with bulb ref. ENN34104				
Packaged by 10 units				
For surface mounted switches	Grey	-	10	ENN35210
	White	-	10	ENN39210
Can be unpacked				
For surface mounted switches	Grey	-	10	ENN35810
Bulbs				
Replacement bulb for illuminated switches or intended to make a switch become illuminated				
Packaged by 10 units				
Bulb 230V - 1,7 mA for surface mounted switches	Grey	-	10	ENN35300
Bulb 230V for flush mounted switches	Grey	-	10	ENN34103
Can be unpacked				
Bulb 230V for flush mounted switches	Grey	-	10	ENN35370
Bulb				
Compatible with flush mounted push-buttons (illuminated or legended).				
Bulb 230V for flush mounted switches	Grey	-	10	ENN34104
Fixing clamps				
5 sets of 2 clamps in each packaging. It can not be mounted on flush mounted time delay switches (ref. ENN34067 and ENN39167), neither on double flush mounted rockers (ref. ENN34012 et ENN34112).				
For flush mounted switches	-	-	1	ENN34102
Additional gasket for flush mounted switches				
Provides IP 44 when installed on a wall with a rough surface (plaster, ...).				
For flush mounted switches	-	-	10	ENN34105
Earth block				
For surface mounted switches	-	-	10	IMT34009