



A range of extension tubes available in Polypropylene or Stainless Steel (316L grade), which extend the reach of the various vertical float switches.

The Polypropylene tubes, with either M12 or M16 threads, are intended for use with our plastic types of float switches and are available in 250mm, 500mm and 750mm lengths.


Stainless steel extension tubes, with either 1/8BSP (G1/8) or 3/8BSP (G3/8), are intended for use with our stainless steel float switches and are available in lengths from 250mm to 1000mm

Cynergy3 Part	Material	Thread type	Extension length	Gasket
EXT02 5M12PP	Polypropylene	M12x1.75	250mm	Nitrile
EXT050M12PP	Polypropylene	M12x1.75	500mm	Nitrile
EXT075M12PP	Polypropylene	M12x1.75	750mm	Nitrile
EXT025M16PP	Polypropylene	M16x2	250mm	Nitrile
EXT050M16PP	Polypropylene	M16x2	500mm	Nitrile
EXT075M16PP	Polypropylene	M16x2	750mm	Nitrile
EXT025G18SS	316 grade SS	G1/8	250mm	Nitrile
EXT050G18SS	316 grade SS	G1/8	500mm	Nitrile
EXT075G18SS	316 grade SS	G1/8	750mm	Nitrile
EXT100G18SS	316 grade SS	G1/8	1000mm	Nitrile
EXT025G38SS	316 grade SS	G3/8	250mm	Nitrile
EXT050G38SS	316 grade SS	G3/8	500mm	Nitrile
EXT075G38SS	316 grade SS	G3/8	750mm	Nitrile
EXT100G38SS	316 grade SS	G3/8	1000mm	Nitrile

Mechanical Dimensions

All dimensions are in millimeters (inches)

Ext. PP Versions

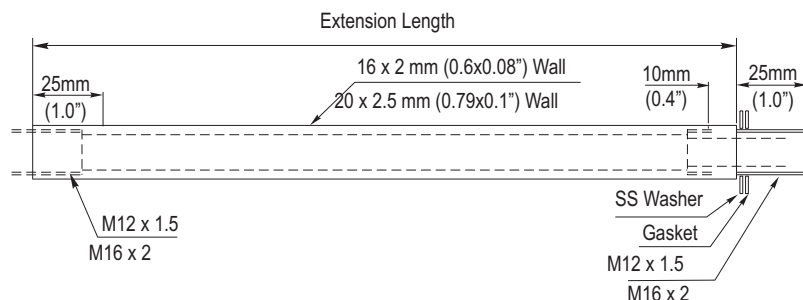

USA

Cynergy3 Components
2320 Paseo de las Americas, Suite 104
San Diego, CA 92154
Sales & Tech Support (866) 258-5057
Email: sales@cynergy3.com

EUROPE - UK

Cynergy3 Components Ltd.
7 Cobham Road
Ferndown Industrial Estate
Wimborne, Dorset BH21 7PE
Telephone +44 (0) 1202 897969
Fax +44 (0) 1202 891918
Email: sales@cynergy3.com

Ext. SS Versions

