


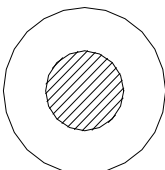

Datasheet

Product Name:	MIL-W-16878/4 28AWG
Product Discription:	MIL-W-16878/4 28AWG
Specification No.:	
Customer's Name:	

Description					Construction						
Rated Voltage:		600V			Conductor		Stranded Sliver plated copper				
Rated Temperature:		200℃			Size(AWG)		28				
Reference Standard:		MIL-W-16878/4			Construction(±0.008mm)		7/0.127				
Cross Section					Stranded Dia.(mm)Ref.		0.38				
					Insulation Material		PTFE				
					Insulation Color		ANY COLOR				
					Ave Thickness(mm)		0.25				
					Insulation Dia.(±0.08mm)		0.89				
Marking					Remark:						
No marking on the cable jacket					8775428 Red		8775424 Blue				
					8775412 Black		8775437 White				
					8775421 Brown						
Applications					Characteristics				Customer Approve		
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.					Test Item			Standard Value			Seal & Stamp Signature: Date:
					Test Material			PTFE(ROHS)			
					Insulation resistance(20℃ MΩ*m			1000			
					Vol. Tesr(AC.V.60S) (V)			2000			
					Flammability Test			Horizontal flame			
Revisions					Max.DC Resistance(20℃ Ω/km)			208.66(MAX)			
Version	Description	Drawn by	Approved by	Date							
0	New document issue	Danniel	Jason	19/05/2015							

Seal & Stamp

Signature:

Date: