
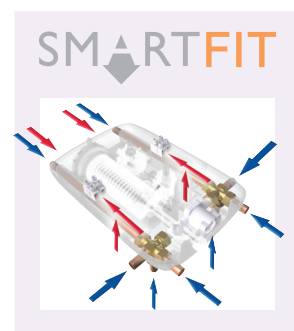


Xpressions

Designed with installers in mind, the innovative Xpressions is the ultimate replacement shower. With 8 water entry points and 6 cable entry points as well as flexible fit accessories, the Xpressions is an ideal choice for those that want a quick and easy installation.

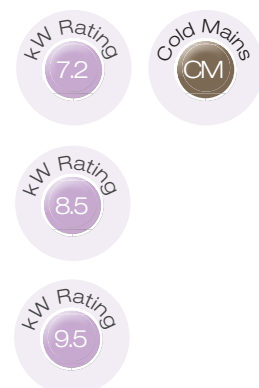

Key Features

- Available in 7.2kW, 8.5kW and 9.5kW
- Transferable terminal block and dual water pipe connection for left or right hand installation flexibility
- Push button start/stop for 'set and forget' operation
- Rotary power select
- Rotary temperature/flow control
- Power on and auto reset neon indicators
- Removable, easy clean inlet filter
- Flexi Kit™ accessories with sliding fixing bracket, ideal for replacements
- Hose, soap dish and 3 mode rub-clean shower head
- 2 year UK guarantee

Technical Specification

- Operating water pressure 1-10 bar (15-150psi)
- Water connection - 15mm plain shank push fit or standard compression fittings
- Transferable terminal block for left or right hand electrical connection
- Smart Fit™ maximum connection options for power and water services
- Removable bottom section for ease of installation
- kW loading at 240V: 7.2 or 8.5 or 9.5
- Recommended cable sizes and fuse ratings:
7.2kW 6mm² 30 Amps
8.5kW 6 - 10mm² 40 Amps
9.5kW 10mm² 45 Amps

Product Range

Product Reference	Model	Cat. No
Xpressions 7.2kW White	X7	53563001
Xpressions 8.5kW White	X8	53563201
Xpressions 9.5kW White	X9	53563401

