


Deep groove ball bearings, single row, seal on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
10	19	5	1,38	0,585	0,025	-	22000	0,0055	61800-2RS1

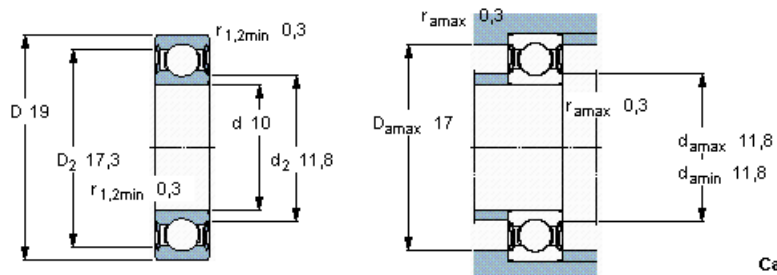

Calculation factors

$k_r = 0,015$

$f_0 = 9,4$