


SS·SS-N SERIES


SS PLASTIC CASE

SS-N FLAME-RESISTANT PLASTIC CASE

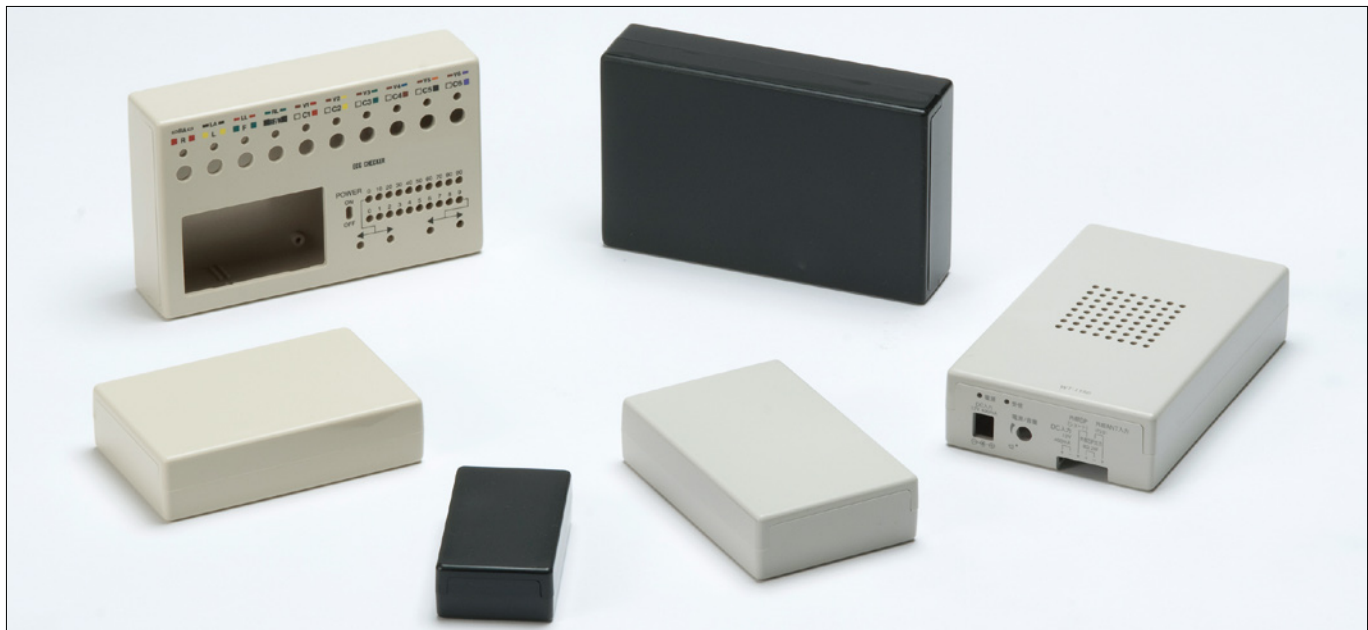

SS Dimensions

SS-90

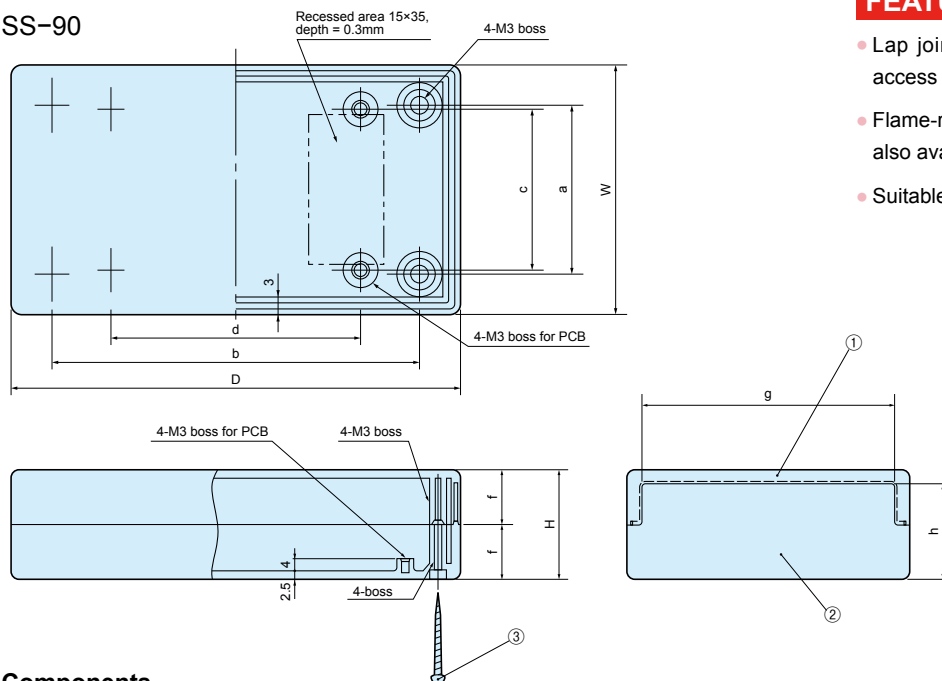



FEATURE

- Lap joint construction provides protection against access of dust and water.
- Flame-resistant (UL94V-0) type in light gray color is also available.
- Suitable PCBs are available.

Components

Ref. #	Part name	Pcs	Material	Color / Finish
1	Top cover	1	ABS (UL94HB · UL94V-0)	Ivory · Black · Light gray
2	Bottom cover	1	ABS (UL94HB · UL94V-0)	Ivory · Black · Light gray
3	Screw	4	M3 Steel	Trivalent chromate

Accessories (Optional parts)

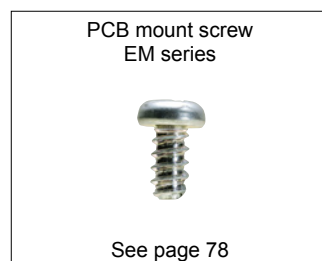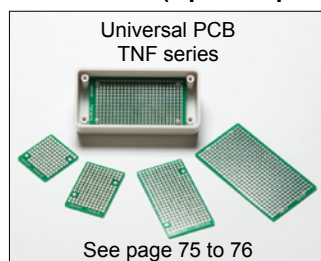


SS Dimensions

• CAD data is downloadable from our web.

SS · SS-N SERIES

SS-125 · 160

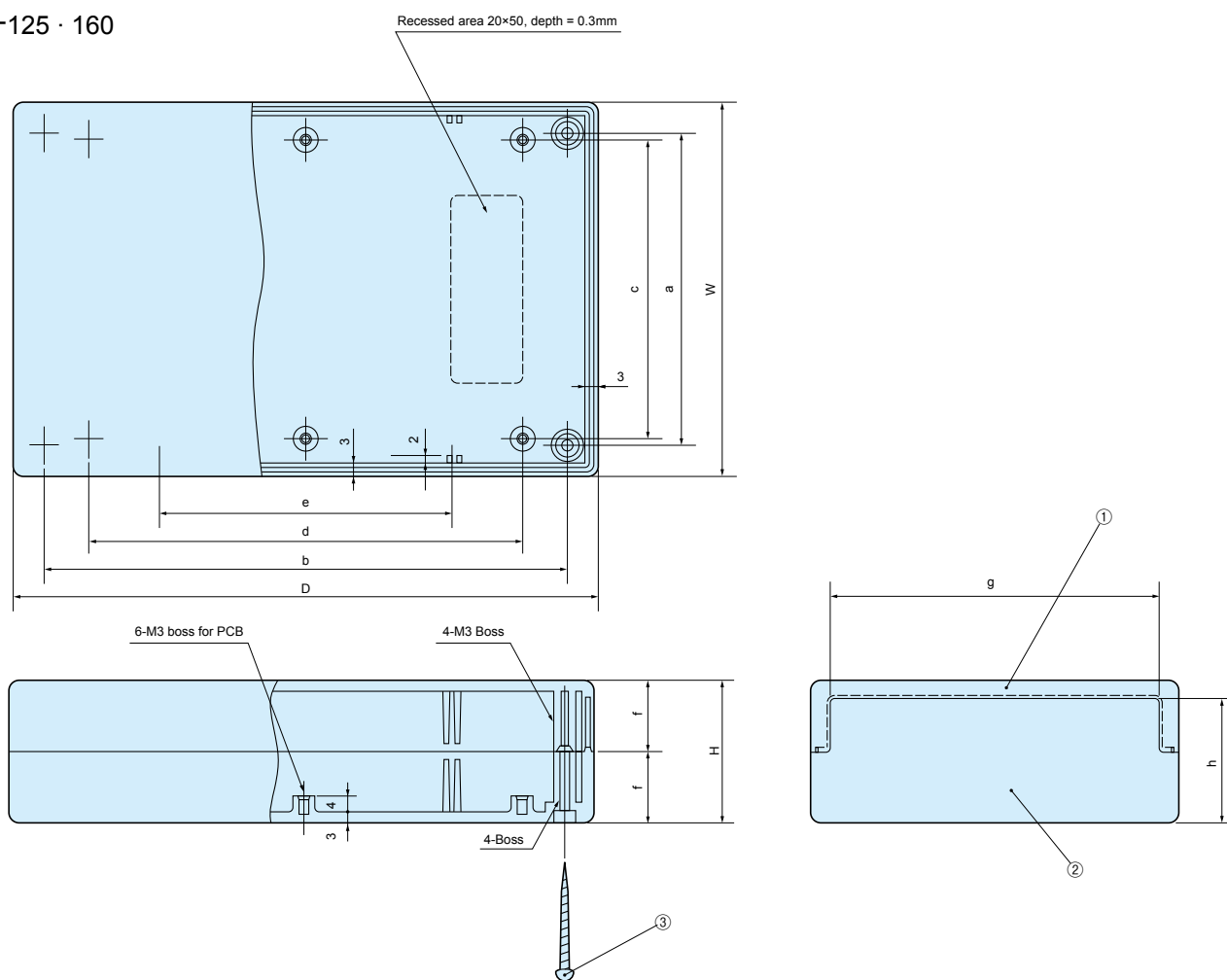**Color Type**

Color code	Color
G	Light gray
A	Ivory
B	Black

SS-N Flame-resistant

ABS UL94V-0

Part no. / Dimensions

Part no.	W	H	D	a	b	c	d	e	f	g	h	Weight(g)
SS-N 90G	50	26	90.3	34	74	30	50	—	13	40	21	55
SS-N125G	80	32	125	64	109	60	85	60	16	70	27	115
SS-N160G	100	38	160	84	144	80	120	80	19	90	33	185

SS Standard

ABS UL94HB

Part no. / Dimensions

Part no.	W	H	D	a	b	c	d	e	f	g	h	Weight(g)
SS- 90A	50	26	90.3	34	74	30	50	—	13	40	21	50
SS- 90B	50	26	90.3	34	74	30	50	—	13	40	21	50
SS- 125A	80	32	125	64	109	60	85	60	16	70	27	100
SS- 125B	80	32	125	64	109	60	85	60	16	70	27	100
SS- 160A	100	38	160	84	144	80	120	80	19	90	33	165
SS- 160B	100	38	160	84	144	80	120	80	19	90	33	165