

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [130299-0100](#)  
**Status:** **Active**  
**Overview:** Brad® Micro-Change® (M12) Connectors  
**Description:** Brad® Micro-Change® (M12) Harsh-Duty Receptacle, 4 Pole, D-Code, Right Angle

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-130299-001 \(PDF\)](#)

**General**

Product Family	Industrial Receptacles
Series	<a href="#">130299</a>
IP Rating	IP67
Overview	<a href="#">Brad® Micro-Change® (M12) Connectors</a>
Product Name	Micro-Change® (M12)
Type	PCB Mount
UPC	78172513052

**Physical**

Coupling Type	Internal Thread
Gender	Female
Keyway	D-coded
Length	N/A
Material - Component	Nickel-plated Zinc Die-Cast
Mounting Thread Size	M12 x 1.0
Orientation	90° Angle
Panel Mount	Back, Front
Poles	4
Temperature Range - Operating	-40°C to +85°C
Wire Size AWG	N/A
Wire/Cable Type	N/A


**Electrical**

Current - Maximum per Contact	4A
Voltage - Maximum	250V AC/DC

**Material Info**

**Reference - Drawing Numbers**

Product Specification	PS-130299-001
Sales Drawing	SD-130299-005

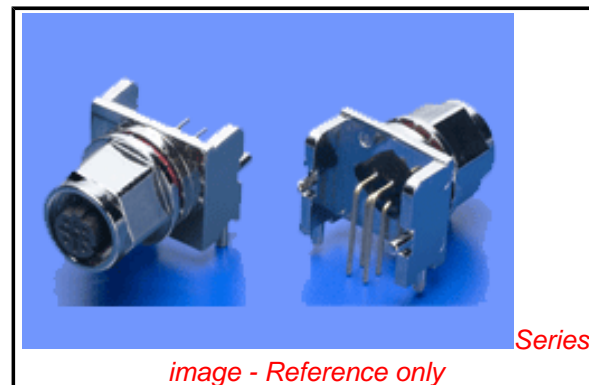

**EU RoHS**

**RoHS Compliant by Exemption**

**REACH SVHC**

Not Reviewed

**Low-Halogen Status**

**Not Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[130299Series](#)

**Mates With**

Male D-Code Cable Assembly