
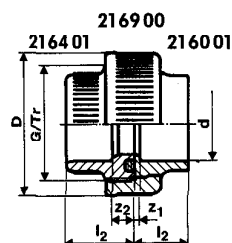


21 51 01

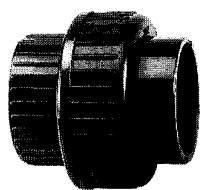

Unions, PVC-U

Plain sockets

Gasket: O-ring No. 48 41 00 EPDM see page 8.13



d	PN	Code	£	SP	GP	g	z ₁	z ₂	G/Tr	D	l ₁	l ₂
10	16	721.510.103	2.60	10	220	20	3	10	5/8"	31	15	22
12	16	721.510.104	2.60	10	220	19	3	10	5/8"	31	15	22
16	16	721.510.105	3.25	10	140	26	3	10	3/4"	35	17	24
20	16	721.510.106	3.85	10	80	42	3	10	1"	43	19	26
25	16	721.510.107	4.40	10	100	67	3	10	1 1/4"	53	22	29
32	16	721.510.108	5.70	10	60	100	3	10	1 1/2"	60	25	32
40	16	721.510.109	7.10	10	30	180	3	12	2"	74	29	38
50	16	721.510.110	9.75	2	60	210	3	14	2 1/4"	83	34	45
63	16	721.510.111	12.60	2	32	360	3	18	2 3/4"	103	41	56
75	10	721.510.112	32.30	2	2	615	3	18	Tr 108x5	135	47	62
90	10	721.510.113	46.90	2	2	925	5	18	Tr 128x5	158	56	69
110	10	721.510.114	60.60	1	1	1425	5	11	Tr 154x6	188	66	72

Unions, PVC-U

Gasket: O-ring No. 49 41 00 FPM see page 8.13

d	PN	Code	£	SP	GP	g	z ₁	z ₂	G/Tr	D	l ₁	l ₂
10	16	721.510.128	3.62	10	100	20	3	10	5/8"	31	15	22
12	16	721.510.129	3.62	10	100	19	3	10	5/8"	31	15	22
16	16	721.510.130	3.75	10	100	26	3	10	3/4"	35	17	24
20	16	721.510.131	4.44	10	80	42	3	10	1"	43	19	26
25	16	721.510.132	5.05	10	100	67	3	10	1 1/4"	53	22	29
32	16	721.510.133	6.60	10	60	100	3	10	1 1/2"	60	25	32
40	16	721.510.134	8.15	10	30	180	3	12	2"	74	29	38
50	16	721.510.135	11.25	2	60	210	3	14	2 1/4"	83	34	45
63	16	721.510.136	14.60	2	32	360	3	18	2 3/4"	103	41	56
75	10	721.510.137	47.25	2	2	615	3	18	Tr 108x5	135	47	62
90	10	721.510.138	54.00	2	2	925	5	18	Tr 128x5	158	56	69
110	10	721.510.139	73.00	1	1	1425	5	11	Tr 154x6	188	66	72

 21 60 01

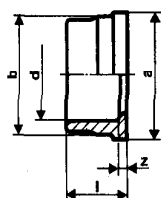

Union Ends, PVC-U

d	PN	Code	£	g	z	l	a	b
10	16	721.600.103	0.38	4	3	15	20.4	18.5
12	16	721.600.104	0.38	4	3	15	20.4	18.5
16	16	721.600.105	0.64	5	3	17	24	22
20	16	721.600.106	0.68	9	3	19	30.1	27.5
25	16	721.600.107	0.95	15	3	22	38.8	36
32	16	721.600.108	0.98	25	3	25	44.7	41.5
40	16	721.600.109	1.45	36	3	29	56.5	53
50	16	721.600.110	2.96	52	3	34	62.6	59
63	16	721.600.111	3.80	90	3	41	78.4	74
75	10	721.600.162	4.78	140	3	47	101	90.5
90	10	721.600.163	5.45	255	5	56	121	108
110	10	721.600.164	6.95	390	5	66	146	131