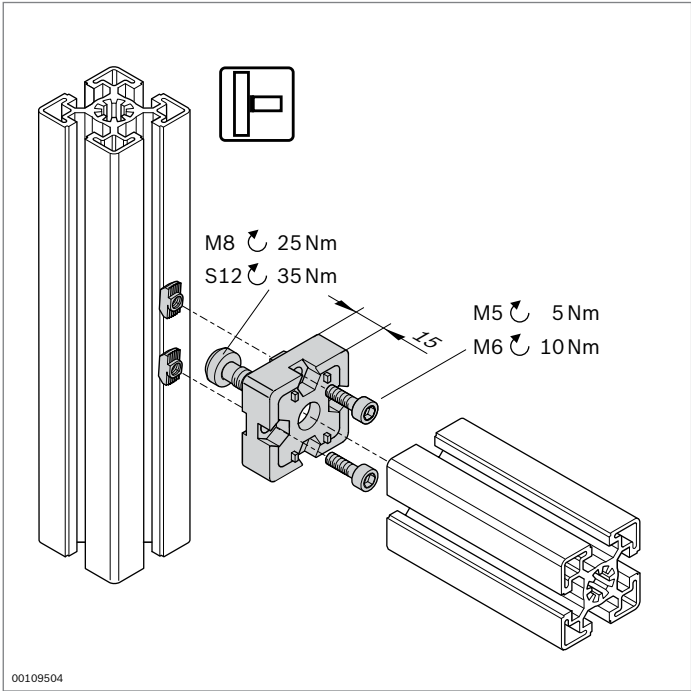
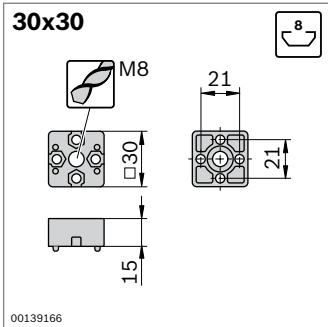


 
 


T-connector



- ▶ For right-angled profile connections
- ▶ *designLINE* version with special silver paint (RAL 9006) for an attractive, high-quality design
- ▶ Profile finishing:
 - 30x30: M8 thread cutting in central bores
 - 40x40, 45x45, 50x50: not required



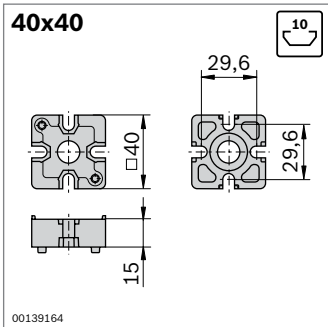
Type	 F_{max}	 M_{max}
30x30	4000 N	80 Nm

 
 
FS1	FS2
 DIN7984 M8x30	 DIN 7984 M5x16

T-connector	Slot	ESD	No.	FS
30x30 Set (standard)	8		3 842 524 476	1xFS1, 2xFS2
<i>designLINE</i> set	8		3 842 538 696	1xFS1, 2xFS2

Material: T-connector: Die-cast aluminum
designLINE T-connector: painted (RAL 9006)
Fastening material: steel; galvanized

Scope of delivery: set incl. fastening material (FS)



Type	 F_{max}	 M_{max}
40x40	9000 N	150 Nm

FS3	FS4
 S12x30	 DIN 7984 M6x20

T-connector	Slot	ESD	No.	FS
40x40 Set (standard)	10		3 842 532 195	1xFS3, 2xFS4
<i>designLINE</i> set	10		3 842 538 697	1xFS3, 2xFS4

Material: T-connector: Die-cast aluminum
designLINE T-connector: painted (RAL 9006)
Fastening material: steel; galvanized

Scope of delivery: set incl. fastening material (FS)