

## ToLEDo Ball

*ToLEDo Ball Frosted 250LM E27 SL*

**0026949**



### Range features

- Up to 80% energy saving compared to incandescent lamps
- Instant light
- Suitable for replacement for 25W and 40W incandescent lamps
- Available in Homelight (2700K)
- Good colour rendering (CRI 80+)
- Average rated life 25,000 hrs



### PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026949
Average life (Rated) (h)	25000
Energy class	A+
Lamp shape	Ball
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	ToLEDo Ball
EAN code	5410288269498
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Watt (Nominal) (W)	4
Equivalent watt (W)	25
Voltage (V)	220-240

## ToLEDo Ball

ToLEDo Ball Frosted 250LM E27 SL

0026949

### DATA TABLE

#### General data

Ordering number	0026949
Dry applications use only	Yes
Technology	LED
Energy saving lamp	Yes
Energy class	A+
Average life (Rated) (h)	25000
Average life (Nominal) (h)	25000
Lamp finish	Frosted
Lamp shape	Ball
Dimmable	No
Cap/Base	E27
Type	ToLEDo Ball
EAN code	5410288269498
E-number SE	8359540
E-number FI	4740201
Long description	Up to 80% energy saving compared to incandescent lamps. Instant light. Suitable for replacement for 25W and 40W incandescent lamps. Available in Homelight (2700K). Good colour rendering (CRI 80+). Average rated life 25,000 hrs
Product name	ToLEDo Ball Frosted 250LM E27 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Intended purpose	No
No. of switching cycles before premature failure (min)	50000
Special purpose lamp	No
Sales pack quantity	6
Optimal operating condition (°C)	25

#### Optical data

Light colour	Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	250

## ToLEDo Ball

*ToLEDo Ball Frosted 250LM E27 SL*

**0026949**

### Electrical data

<b>kWh per 1000 hours burning time</b>	4
<b>Equivalent watt (W)</b>	25
<b>Watt (Rated) (W)</b>	4
<b>Watt (Nominal) (W)</b>	4
<b>Voltage (V)</b>	220-240
<b>Current (A)</b>	0.024
<b>Lamp power factor</b>	0.7

### Physical data

<b>Weight (kg)</b>	0.05
<b>Lamp Length (mm) - C/L</b>	79
<b>Max. Lamp Diameter (mm) - D</b>	45
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	9.50 x 4.80 x 4.80
<b>Inner package dimensions (L x W x H) (cm)</b>	15.50 x 10.50 x 11.00
<b>Inner package net weight (kg)</b>	0.27
<b>Outer package dimensions (L x W x H) (cm)</b>	55.00 x 32.60 x 13.00


## ToLEDo Ball

*ToLEDo Ball Frosted 250LM E27 SL*

**0026949**

### TECHNICAL DRAWINGS

---

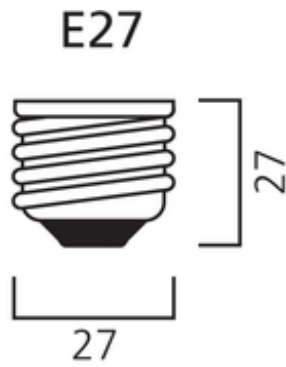

### ENERGY LABEL

---

□