


Deep groove ball bearings, single row, unsealed

Product information

Tolerances , see also text
 Radial internal clearance , see also text
 Recommended fits
 Shaft and housing tolerances

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
55	90	18	29,6	21,2	0,9	16000	10000	0,39	6011 *

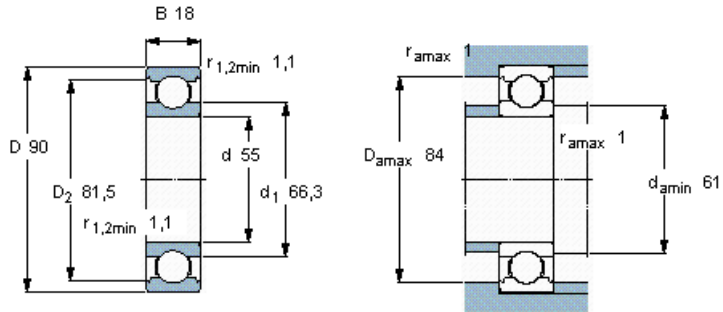

Calculation factors
 k_f 0,025
 f_0 15