




ENGLISH

Datasheet

Stock No: 335-536

# RS Pro Proximity Switch, Surface Mount, 500mA, 50V dc, 38 x 14 x 8.7mm

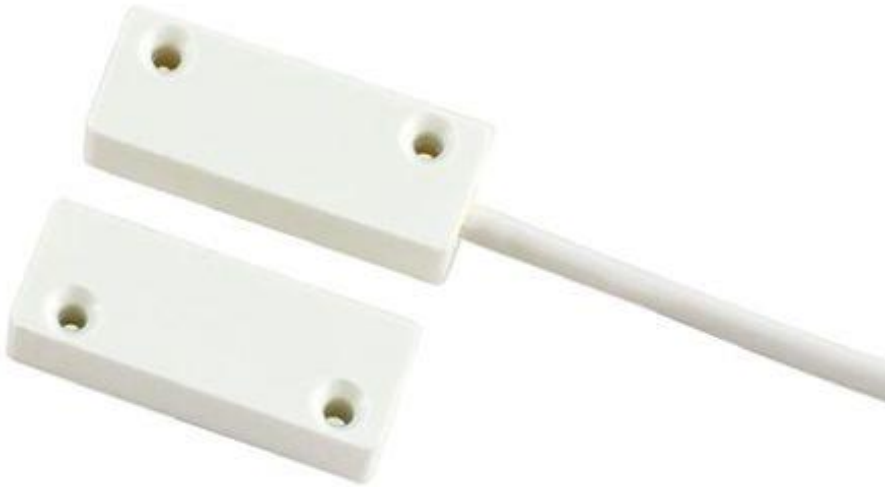

## Product Details

### Surface Mount Alarm Switch - Magnetic

Cable type or terminal type surface mount switches. Cable type comes fitted with 300mm long cable. Proximity switches primarily designed for discrete protection of doors and windows. The switches are of moulded construction incorporating a N/O SPST magnetically operated reed switch. The permanent actuating magnet is also of moulded construction to facilitate easy fixing. All switches have a separate tamper loop or terminals for maximum security as described in BS 4737.

Set includes magnet and proximity switch

### Standards

BS 4737 Part 3



ENGLISH

## Specifications:

Activation Type	Proximity Switch
Mounting Type	Surface Mount
Switch Configuration	Normally Open
Switching Current	500mA
Switching Voltage	50V dc
Operating Gap	15mm
Depth	8.7 mm
Height	38 mm
Operating Gap Maximum	15mm
Width	14mm